



EURONORD 3



PC/ABS 3 1534

IP and IK classifications page 32
IP und IK Klassifikationen

Technical information page 33
Technische Eigenschaften

Material properties and performance pages 34-35
Material Vor-/Nachteile und Materialeigenschaften

Gaskets page 36
Gehäusedichtunge

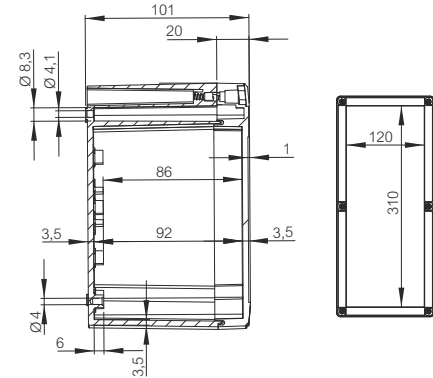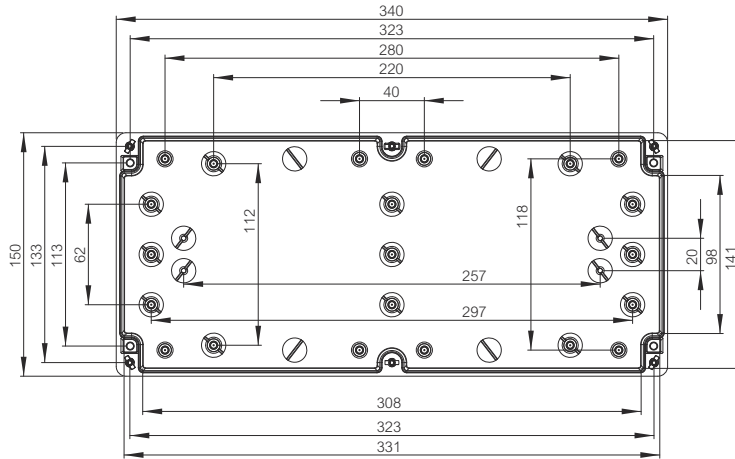

	Dimensions, mm Abmessungen, mm	Order symbol Bestellzeichen	Code & EAN Artikel-Nr. & EAN	Description Beschreibung
PC IP66/IP67 IK07/IK08	340x150x101	PCQ3 153410	7035701 6418074099136	Grey cover (quick-locking) grauer Deckel (QuickLock)
	340x150x101	PCTQ3 153410	7025700 6418074099143	Smoked transparent cover (quick-locking) rauchgrau transparenter Deckel (QuickLock)
ABS IP66/IP67 IK07	340x150x101	ABQ3 153410	7085701 6418074099129	Grey cover (quick-locking) grauer Deckel (QuickLock)
Accessories Zubehör	303x136	TM 1534	9512021 6418074059437	Mounting plate Montageplatte
	35x307	TRH 34	9822022 6418074059697	DIN-35 Mounting rail Tragschiene TS 35
	35x122	TRH 15	9822021 6418074059680	DIN-35 Mounting rail Tragschiene TS 35
		TF 28037	7028337 6418074033734	Wall fastening lug (4 pcs) incl. screws Befestigungslasche 4 St. mit Schrauben
		TH A	9802001 6418074034120	Grey plastic hinges (2 pcs) incl. mounting screws Plastik-Scharniere, grau 2 Stück mit Schrauben
		EU 3 QuickLock set 60	7028244 6418074306340	QuickLock screws (60 pcs) QuickLock Deckelschrauben (60 St.)
		MR 28036EU Set 60	7028236 6418074306357	Mounting screws (60 pcs) Montageschrauben (60 St.)
		EU 3 Plug set 60/30	7038240 6418074305947	EU 3 Cover screw plug set 60/30 EU 3 Deko-Pfropfen set 60/30
		EU 3 Plug set 60/30 BL	7038242 6418074305831	EU 3 Cover screw plug set 60/30 black EU 3 Deko-Pfropfen set 60/30 schwarz

Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and quick-locking cover screws.
Besteht aus: Unterteil inkl. Montageschrauben, Deckel inkl. PUR Dichtung und Schnellverschluß-Deckelschrauben.