



DC311XX
DC313XX

 
GB Contents DE Inhalt FR Contenu NL Inhoud FI Sisältö
 UK Inhold IT Contenuto ES Contenido PT Conteúdo
 CZ Obsah SE Innehåll HU Tartalom PL Zawartość
 HR Sadržaj RO Conținut SK Obsah



x1



x1



x1



x1



x1


CR2032







x2




x1

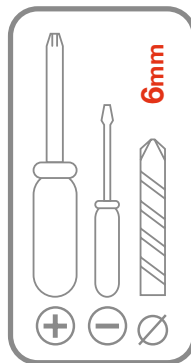


GB Getting started DE Erste Schritte FR Démarrage NL Aan de slag FI Aloitusohje
 UK Getting started IT Operazioni preliminari ES Para comenzar PT Para começar
 CZ Úvodní operace SE Förberedelse HU Bevezetés PL Przygotowanie do użycia
 HR Početak rada RO Noițiuni de bază SK Záči name

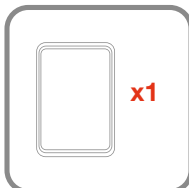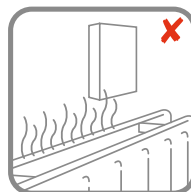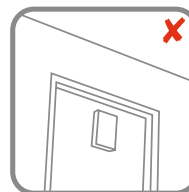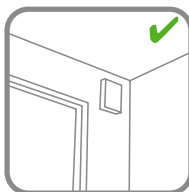



x1

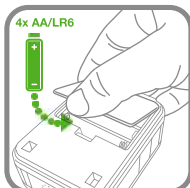


4x AA/LR6

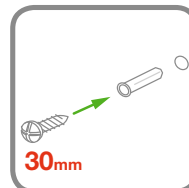




30mm

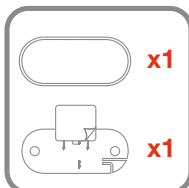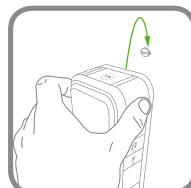



x1

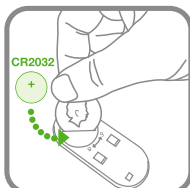



CR2032

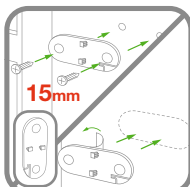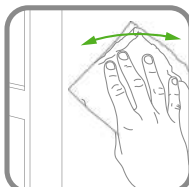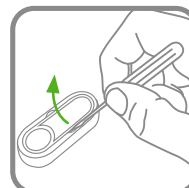

15mm

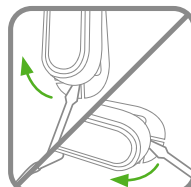
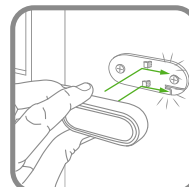


GB Optional features **DE** Optionale Funktionen **FR** Options disponibles **NL** Opties
FI Valinnaiset ominaisuudet **SK** Voliteľné funkcie **IT** Funzionalità opzionali
ES Opciones disponibles **PT** Funções opcionais **CZ** Volitelné funkce
SE Möjliga funktioner **HU** Opcionális funkciók **PL** Funkcje dodatkowe
HR Dodatne značajke **RO** Caracteristici optionale **SK** Voliteľné funkcie

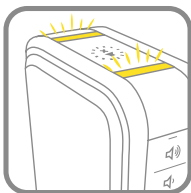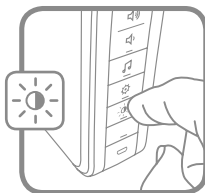

	Hello	Ding dong	Westminster	Marimba	Piano	Bell	Telephone	Soft alert	Glocken	Click ding dong	Contemporary
	•	•					•	•			
	•	•		•			•	•			
	•	•		•	•	•	•	•			
	•	•	•				•	•	•	•	•
	•	•	•	•	•	•	•	•	•	•	•

GB Linking **DE** Verbinden **FR** Liaison
NL Koppelen **FI** Linkitys **SK** Pripojenie
IT Collegamento **ES** Enlace **PT** Ligação
CZ Párování **SE** Länkning **HU** Összehangolás
PL Połączenie **HR** Povezivanje
RO Conectare **SK** Párovanie

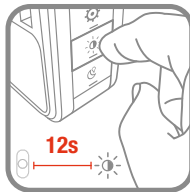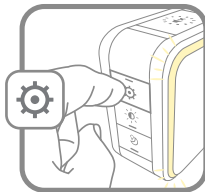

GB Download full guide **DE** Vollständige Anleitung herunterladen
FR Télécharger le guide complet **NL** Volledige handleiding downloaden
FI Lataa koko opas **SK** Download den komplette vejledning
IT Scarica la guida completa **ES** Descargar la guía completa
PT Transferir guia completo **CZ** Stáhnout podrobnou příručku
SE Ladda ned hela guiden **HU** Töljes útmutató letöltése
PL Pobierz pełny przewodnik **HR** Preuzmite cijeli vodič
RO Descărcati ghidul complet **SK** Stiahnuť podrobnú príručku



GB Trouble shooting **DE** Fehlerbehebung **FR** Dépannage **NL** Probleemoplossing
FI Vianmääritys **SK** Problemløsning **IT** Risoluzione dei problemi
ES Solución de problemas **PT** Resolução de problemas **CZ** Odstránění poruch
SE Felsökning **HU** Hibakeresés **PL** Usuwanie usterek **HR** Rješavanje problema
RO Depanare **SK** Riešenie problémov

livewell.honeywellhome.com



32305352-001 Rev_D

© 2020 Resideo Technologies, Inc. All rights reserved.
 The Honeywell Home trademark is used under the license from Honeywell International Inc.
 This product is manufactured by Resideo Technologies, Inc. and its affiliates.