

PERFECT Kabelverschraubung || PERFECT cable gland

K345-1xxx-zz

TECHNISCHE DATEN:

Aufbau

Hutmutter Polyamid PA6 V-2
 Dichteinsatz NBR/SBR, geschlitzt
 Zwischenstutzen Polyamid PA6 V-2
 Anschlussgewinde metrisch, nach EN 60423

Eigenschaften

- durch den geschlitzten Dichtring können Kabel und Leitungen mit fest montierten Steckern (z.B. RJ-45, USB, etc.) einfach und sicher installiert werden
- geeignet für Rundstecker mit Durchmesser bis 17 mm und Rechteckstecker mit Diagonale bis 16,5 mm
- integrierte Zugentlastung
- großer Dicht- und Klemmbereich
- montagefreundlich

Temperaturbereich -20 °C / +70 °C (dynamisch)
 -40 °C (statisch, kurzzeitig)

Schutzart IP65

TECHNICAL DATA:

Configuration


Dome nut Polyamide PA6 V-2
 Sealing insert NBR/SBR, slotted
 Gland body Polyamide PA6 V-2
 Connecting thread metric, as per EN 60423

Properties

- the slotting sealing ring enables cables and leads with fixed connectors (e.g. RJ-45, USB, etc.) to be installed simply and securely
- suitable for circular connectors with diameter up to 17 mm and connectors with rectangular crosssection and diagonal up to 16,5 mm
- integrated anchorage
- wide sealing and clamping range
- easy-to-install

Temperature range -20 °C / +70 °C (dynamic)
 -40 °C (static, short term)

Protection grade IP65

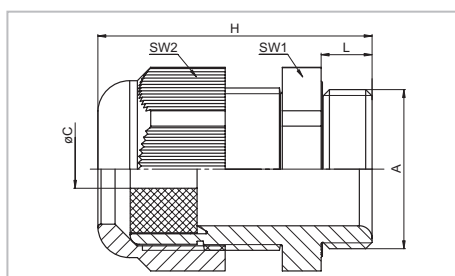


Merkmale

Characteristics

Anschlussgewinde Standardlänge

Connecting thread standard length

A	øC	L	SW1	SW2	H		RAL 7001 silbergrau silver grey Art.-Nr. / Part No.	RAL 7035 lichtgrau light grey Art.-Nr. / Part No.	RAL 9005 tiefschwarz jet black Art.-Nr. / Part No.
M25x1,5	3 - 8	8	29	29	43		K345-1025-01	K345-1025-00	K345-1025-02

Typen auch aus Messing oder Edelstahl lieferbar

Types also available in brass or stainless steel