

# BASETech


## Lampenfassung G9 G9 bulb holder Douille d'ampoule G9 Lampfitting G9 Portalampada G9 Oprawa lampy G9

distributed by  
Conrad Electronic SE  
Klaus-Conrad-Str. 1,  
D-92240 Hirschau



# BASETech

NF. 1465109

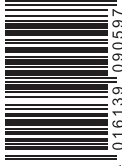

021916\_09\_V2

97040669

- |   |   |   |
|---|---|---|
| <b>(D)</b> Lampenfassung G9<br>Technische Daten:<br>Betriebsspannung/-strom:<br>250 V/AC, 2 A · Leistung: max.<br>500 W · Abmessungen (Ø x H):<br>24,1 x 21,5 mm    | <b>(GB)</b> G9 bulb holder<br>Technical data: Operating<br>voltage/current: 250 V/AC,<br>2 A · Power: max. 500 W ·<br>Dimensions (Ø x H):<br>24,1 x 21,5 mm       | <b>(E)</b> Douille d'ampoule G9<br>Données techniques :<br>Tension/courant de service :<br>250 V/CA, 2 A · Puissance :<br>max. 500 W · Dimensions<br>(Ø x H) : 24,1 x 21,5 mm |
| <b>(IT)</b> Portalampada G9<br>Dati tecnici: Corrente/<br>tensione di esercizio: 250<br>V/CA, 2 A · Potenza: max.<br>500 W · Dimensioni (Ø x A) :<br>24,1 x 21,5 mm | <b>(NL)</b> Lampfitting G9<br>Technische gegevens:<br>Bedrijfspanning/-stroom:<br>250 V/AC, 2 A · Vermogen:<br>max. 500 W · Afmetingen<br>(Ø x H): 24,1 x 21,5 mm | <b>(PL)</b> Oprawa lampy G9<br>Dane techniczne:<br>Napięcie/prąd roboczy:<br>250 V/AC, 2 A · Moc: maks.<br>500 W · Wymiary (Ø x wys.):<br>24,1 x 21,5 mm                      |