

FICHE TECHNIQUE
CP500




Longueur (mm)	Largeur (mm)	Hauteur (mm)	Passe câble (mm)	Poids (kg)
500	500	80	2 x ø 50	14.5

Fabriqué en : caoutchouc
Coloris : noir et blanc

Gamme : SIGN
Code usine : J6
Code douane : 4016999790
EAN : 3321360006592

Caractéristiques :

- Protège câble et tuyaux pour véhicules lourds
- Equipé de 4 réflecteurs et 2 dents de requins qualité 3M pour une bonne visibilité
- 2 passes câbles de diamètre ø 50 mm
- H de liaisons en option
- Fixations asphalte (réf : SPIKES) ou béton (réf : FIX4SB) en option, collage possible (réf : RQGLUE)
- Eviter le contact prolongé aux hydrocarbures
- Fabriqué 100% en caoutchouc
- Température d'utilisation -40/+60°C
- Résiste au passage de véhicules jusqu'à 40T
- Vitesse de franchissement conseillée : 5/10 km/h

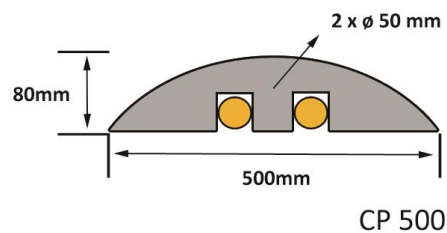

TECHNICAL SHEET

CP500



Length (mm)	Width (mm)	Height (mm)	Cable protection (mm)	Weight (kg)
500	500	80	2 x ø 50	14.5

Made of: rubber
Colors: black and white

Range: SIGN
Factory: J6
Custom: 4016999790
EAN: 3321360006592

Specifications:

- Heavy duty cable and hose protection
- 4 eyes cat and 2 reflective arrows 3M quality
- 2 cable grooves with diameter ø 50 mm
- Links as option
- Asphalt fixations (ref: SPIKES) or concrete (ref: FIX4SB) as option, adhesive bonding is possible (ref: RQGLUE)
- Avoid over long contact with hydrocarbons
- Made of 100% rubber
- Use temperature: -40/+60°C
- Can support vehicles up to 40 Tons
- Advised speed of crossing: 5/10 km/h

