

FICHE TECHNIQUE
CP5040





Longueur (mm)	Largeur (mm)	Hauteur (mm)	Poids (kg)
500	400	40	4

Fabriqué en : caoutchouc
Coloris : noir

Gamme : SIGN
Code usine : J6
Code douane : 4016999790
EAN : 3321360010124

Caractéristiques :

- Passe-câble piéton
- Fabriqué en caoutchouc semi rigide
- Coloris noir
- 7 passes-câbles (2 passes-câbles $\varnothing 20$ mm ; 5 passes-câbles $\varnothing 25$ mm)
- 2 bandes blanches réfléchissantes classe 1
- Résiste au passage de véhicules jusqu'à 2T par essieu
- 4 fixations ($\varnothing 6$ mm) CP 5 FIX SB en option
- Emboitage male/femelle
- Températures d'utilisation $-40^{\circ}/+60^{\circ}\text{C}$

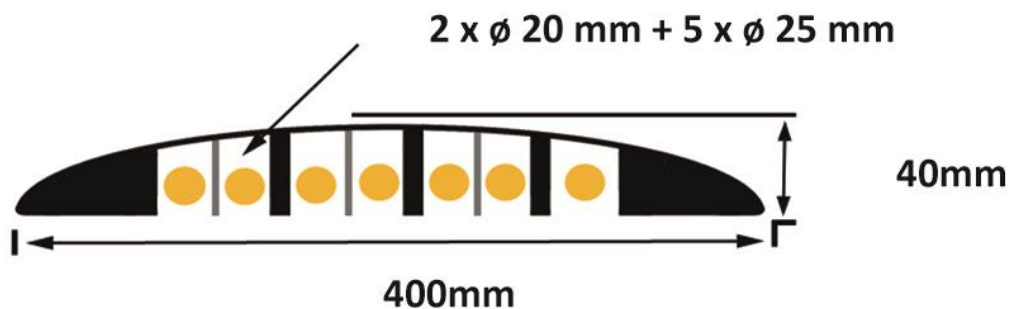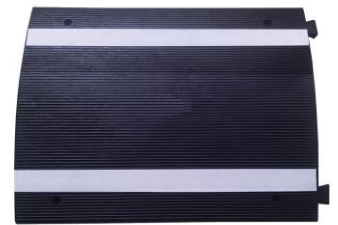

TECHNICAL SHEET
CP5040



Length (mm)	Width (mm)	Height (mm)	Weight (kg)
500	400	40	4

Made of: rubber
Colors: black

Range: SIGN
Factory: J6
Custom: 4016999790
EAN: 3321360010124

Specifications:

- Pedestrian cable protection
- Made of half hard rubber
- Color: black
- 7 cable grooves (2 cable grooves $\varnothing 20$ mm; 5 cable grooves $\varnothing 25$ mm)
- 2 reflective white stripes class 1
- Resist to vehicles up to 2T
- 4 fixations ($\varnothing 6$ mm) CP 5 FIX SB as option
- Male/female links
- Using temperature $-40^{\circ}/+60^{\circ}\text{C}$

