

**FICHE TECHNIQUE**  
WP100



Longueur (mm)	Largeur (mm)	Hauteur (mm)	Poids (kg)	Passes-câbles	Jusqu'à
10000	100	30	15.5	1 x Ø20 mm	40 T

**Fabriqué en :** caoutchouc  
**Coloris :** noir


**Gamme :** SIGN  
**Code usine :** J6  
**Code douane :** 4016999790  
**EAN :** 3321369963186

**Autres :**

- Passe câble ralentisseur
- Diamètre Ø 20 mm du passe câble
- Idéal pour les installations provisoires
- Utilisation intérieur/extérieur
- Possibilité de couper à la longueur souhaitée
- Résiste aux véhicules jusqu'à 40 T
- Éviter le contact prolongé avec des hydrocarbures
- Résiste aux températures de -40/+60°C
- Fixation par collage possible réf RQGLUE (non fournie)



RQGLUE

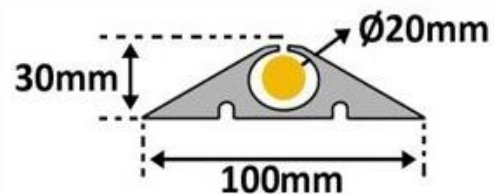

## TECHNICAL SHEET

WP100



Length (mm)	Width (mm)	Height (mm)	Weight (kg)	Cable protection	Up to
10000	100	30	15.5	1 x ø20 mm	40 T

**Made of :** rubber

**Colors :** black

**Range:** SIGN

**Factory:** J6

**Custom:** 4016999790

**EAN :** 3321369963186

**Others :**

- Heavy duty cable protection
- Diameter ø 20 mm cable bridge
- Ideal for temporary installations
- Indoor/Outdoor use
- Can be cut to the desired length
- It can support vehicules up to 40 T
- Avoid prolonged contact with hydrocarbons
- Resist to temperature between -40/+60°C
- Adhesive bonding is possible with ref: RQGLUE (option)



RQGLUE

