
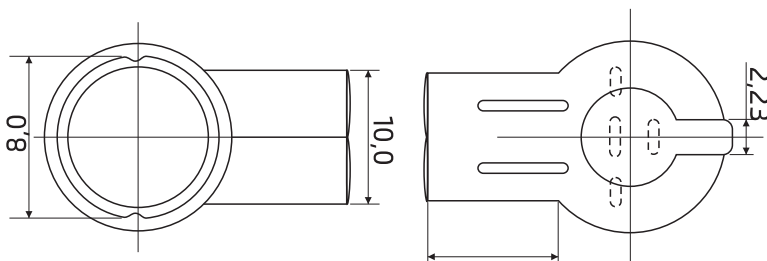
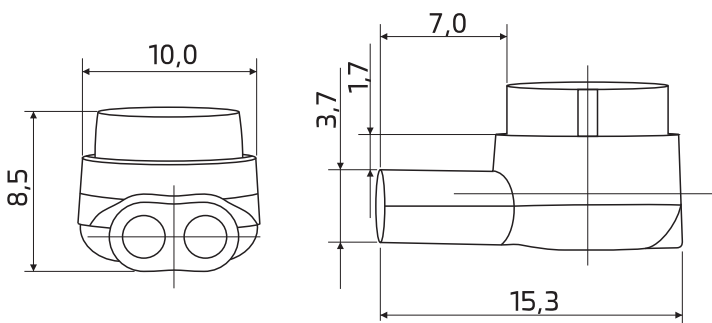


Data Sheet

Grease filled Lock Joint Wire Connector AWG 26 - 19, Self-stripping Tab 100pcs Box Set

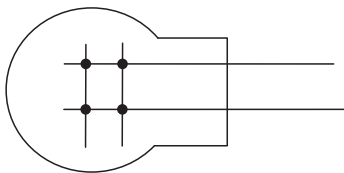

Specification

Insulation material: PC

Contact material: Tinned Brass

Color: Yellow cap / Transparent base

Wire range: AWG 26 - 19 (0.13-0.65mm²)

Wire outer diameter: 2.08 mm (max.)

Conductor diameter: 0.4 ~ 0.9 mm

Voltage rating: 50V/AC, 75V/DC max.

Current rating: 1.5A max

Working temperature: 0-65°C

Working humidity: 95% RH

Package qty.: 100pcs