
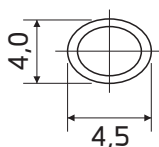
 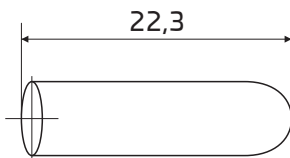


Data Sheet

Grease Filled Single Wire Connector



Specification

Insulation material: PVC

Contact material: Phosphor bronze

Color: Blue

Wire range: AWG 26 -22

Insulation diameter: 1.27 mm (max.)

Conductor diameter: 0.08 ~ 0.38 mm

Voltage rating: < 50V/AC, 75V/DC

Current rating: 3A max.

Working temperature: 0-65°C

Working humidity: 95% RH

Package qty.: 100pcs