


Data Sheet

Mini Solar cell panel

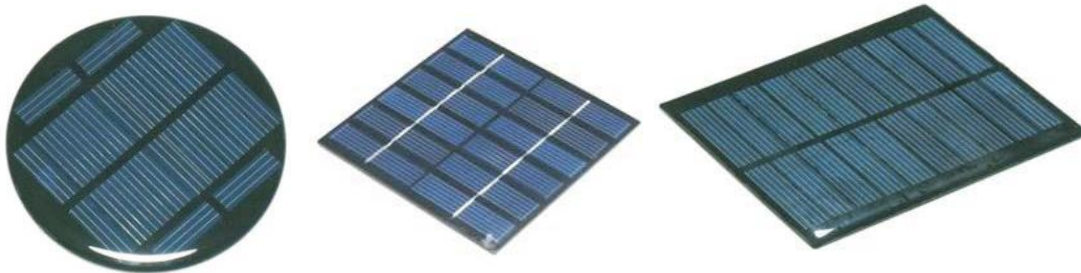

Item no.	Dimension	Thickness	SolarcellType	Maximum	Power	RatedVoltage	Rated	OpenCircuit	ShortCircuit	NetWeight
	(±0.3)	(±0.3)		Power(P.max)	Tolerance	(V.mp)	Current(Imp)	Voltage(Voc)	Current(Isc)	Approx.
1572739	Φ56mm	2.7mm	Polycrystalline	0.2W	±5%	2V	0.1A	2.4V	0.105A	0.008kg
1565764	Φ70mm	2.9mm	Polycrystalline	0.24W	±5%	2V	0.12A	2.4V	0.126A	0.014kg
1569022	49x49mm	3.1mm	Polycrystalline	0.2W	±5%	2V	0.1A	2.4V	0.055A	0.01kg
1569023	55x55mm	3.1mm	Polycrystalline	0.23W	±5%	2.5V	0.09A	3V	0.092A	0.011kg
1572740	80x80mm	3.1mm	Polycrystalline	0.8W	±5%	2V	0.4A	2.4V	0.42A	0.033kg
1565765	80x80mm	3.1mm	Polycrystalline	0.8W	±5%	4V	0.2A	4.8V	0.21A	0.031kg
1569024	80x80mm	2.9mm	Polycrystalline	0.6W	±5%	5V	0.12A	6V	0.126A	0.031kg
1569025	18x30mm	3.1mm	Polycrystalline	0.04W	±5%	0.5V	0.08A	0.52V	0.165A	0.004kg
1564741	30x60mm	2.7mm	Polycrystalline	0.1W	±5%	2V	0.05A	2.4V	0.053A	0.005kg
1565766	30x70mm	2.7mm	Polycrystalline	0.2W	±5%	5V	0.04A	2.4V	0.042A	0.007kg
1570491	30x90mm	2.7mm	Polycrystalline	0.3W	±5%	6V	0.05A	7.2V	0.053A	0.01kg
1569026	59.5x62.5mm	3.1mm	Polycrystalline	0.04W	±5%	5V	0.08A	5.5V	0.01A	0.012kg
1564742	20x106mm	3.1mm	Polycrystalline	0.13W	±5%	2V	0.065A	2.2V	0.036A	0.015kg
1569027	60x100mm	2.8mm	Polycrystalline	0.72W	±5%	6V	0.12A	7.2V	0.126A	0.02kg

- Material: Polycrystalline Silicon
- Spectral range: 38000 – 40000 lx
- Operating Temperature: -20°C~80°C
- Storage Temperature: 10°C~65°C
- Operating Humidity: 25%~95%RH
- Storage Humidity: 15%~75%RH