


Data Sheet

Butt joint + heatshrink



Maximum Electric Rating:	600V
Maximum Electric Current	
22-16AWG/0.5-1.5mm ² :	19A
16-14AWG/1.5-2.5mm ² :	27A
12-10AWG/4-6mm ² :	48A
Shrinking Temperature:	≥150°C
Operating Temperature:	-40°C ~ 120°C
Shrinking Ratio:	3:1
Terminal Body:	Copper
Insulation:	PE
Plating:	Tin

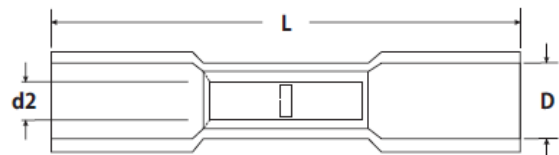

Wire Range mm ² /Awg	Item No.	Dimension(mm)			Insulation Color
		L	D	d2	
0.5-1.5mm ² 22-16AWG	1572151	33.3	4.0	1.7	Transparent
0.5-1.5mm ² 22-16AWG	1566810	33.3	4.0	1.7	Red
1.5-2.5mm ² 16-14AWG	1566811	34.3	5.5	2.3	Blue
4-6mm ² 10-12AWG	1564469	41.0	6.4	3.4	Yellow