
 
 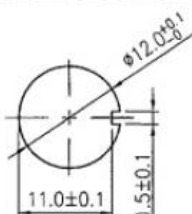



Data Sheet


TRU COMPONENTS vehicle toggle switch green (R13-423L)



Rating	30A 12V DC	Mounting Hole 	Circuit Diagram	
Contact Resistance	50m ohm Max.		OFF	
Insulation Resistance	DC 500V 100M ohm Min.		ON	
Dielectric Strength	AC 1500V 1 minute			
Operation Temperature	-20° C~85° C			
Switch Function	3P SPST ON-OFF (LED dependent)			

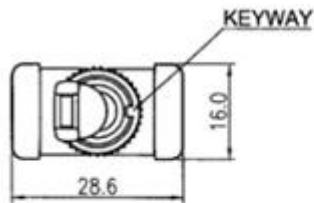

- 1 HEX NUT ASSY
- 1 SPRING WASHER ASSY
- 1 KNURL NUT ASSY

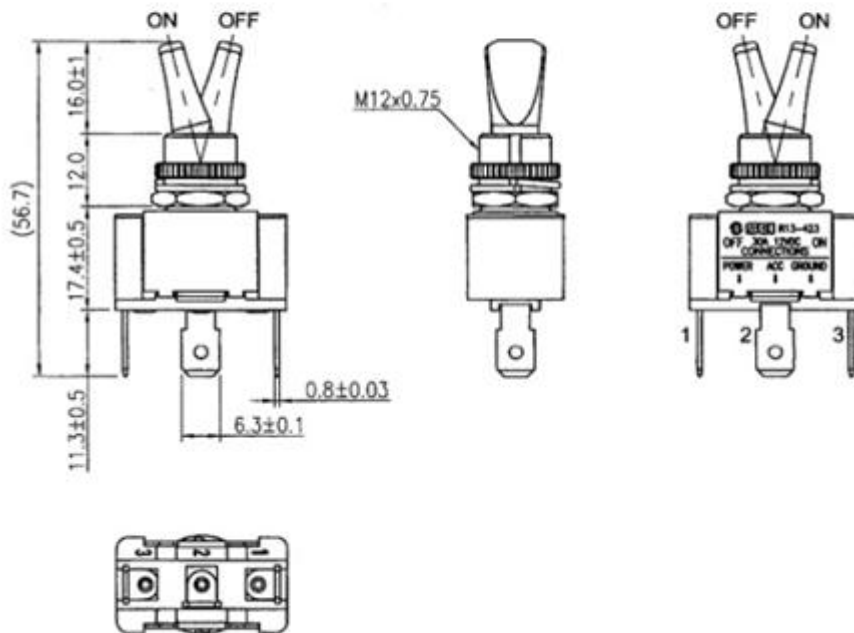

Tolerances ±0.3 Unless Otherwise Specified