 
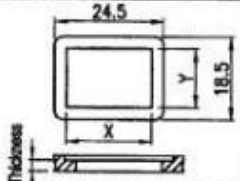

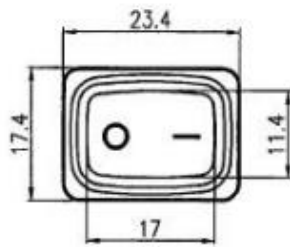


# Data Sheet

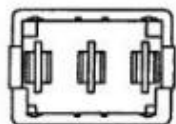
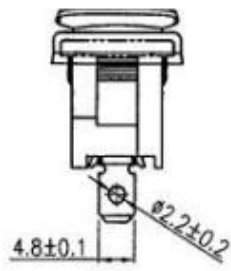
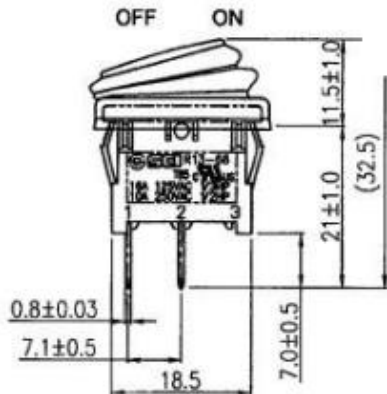
## Rocker Switch

Rating	16A 125V AC 1/3HP		Mounting Hole	Circuit Diagram
	10A 250V AC 1/2HP			
Contact Resistance	50m ohm Max.			
Insulation Resistance	DC 500V 100M ohm Min.			
Dielectric Strength	AC 1500V 1 minute			
Operation Temperature	-25°C~85°C			
Switch Function	2P SPST ON-OFF		Thickness	
			X	Y
			0.75~1.25	19.4~0.1
			1.5~2.5	19.8~0.1



Soldering time: within 3 seconds  
 Soldering temperature: 320±20 °C (40 W of soldering iron)  
 360±20 °C (60 W of soldering iron)  
 400±20 °C (80 W of soldering iron)

Material:  
 Frame: Black, Nylon#66  
 Actuator: Black, PC  
 Waterproof Rubber: Black, Silicone  
 Waterproof: IP65  
 Terminals: Silver plated, Copper Alloy



Tolerances ±0.3 Unless Otherwise Specified