


# Datasheet

Item no. TC-MS21

### SPECIFICATIONS:

- Rating: 10A 125VAC OR 250VAC
- Contact resistance: 15m $\Omega$  max. (initial)
- Insulation resistance: 100M $\Omega$  min. (at 500VDC)
- Dielectric strength: 1,000VAC 50/60Hz for 1 minute.
- Service life
- Mechanically: 1,000,000 operations min.
- Electrically: 100,000 operations min. (full load)

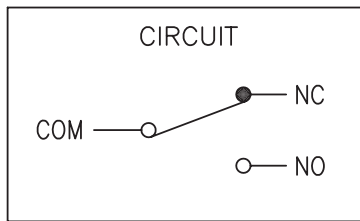

OF max:	115 g
RF min:	14 g
PT max:	3.7 mm
OT min:	1.6 mm
MD max:	1.2 mm
OP :	20.7 $\pm$ 1.2 mm

