

Datasheet

Item no. TC-MK244Z

Specification


1. Rating:3A 125VAC;1.5A 250VAC
2. Contact resistance:20mΩ max
3. Insulation resistance:500VDC 1000MΩ min
4. Dielectric strength:1000VAC,1Minute
5. Operating Temperature:-25°C~+85°C
6. Electrical Life:10,000 Cycles




Circuitry trait

02 | ON | - | ON |

Bushing options

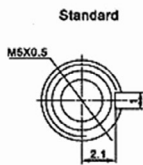


Handle options

 

Terminal options



Nameplate

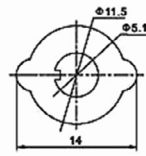

(1)	ON	-	OFF
(2)	ON	-	ON
(3)	ON	OFF	ON

