


# Datasheet

Item no. TC-MS20

**SPECIFICATIONS:**

Rating: 10A 125VAC OR 250VAC  
 Contact resistance: 15mΩ max. (initial)  
 Insulation resistance: 100MΩ min. (at 500VDC)  
 Dielectric strength: 1,000VAC 50/60Hz for 1 minute.  
 Service life  
 Mechanically: 1,000,000 operations min.  
 Electrically: 100,000 operations min. (full load)

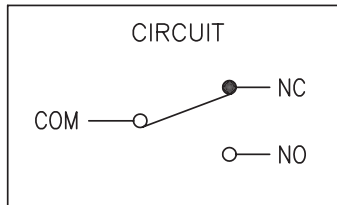

OF max:	230 g
RF min:	56 g
PT max:	1.6 mm
OT min:	0.8 mm
MD max:	0.15~0.4 mm
OP :	14.70±0.4 mm

