


Datasheet

Item no. TC-MS23

SPECIFICATIONS:

Rating: 10A 125VAC OR 250VAC
 Contact resistance: 15mΩ max. (inital)
 Insulation resistance: 100MΩ min. (at 500VDC)
 Dielectric strength: 1,000VAC 50/60Hz for 1 minute.
 Service life
 Mechanically: 1,000,000 operations min.
 Electrically: 100,000 operations min. (full load)

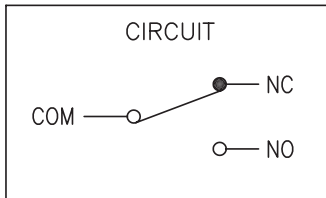

OF max:	115 g
RF min:	14 g
PT max:	3.7 mm
OT min:	1.6 mm
MD max:	1.2 mm
OP :	15.2±1.2 mm

