

Ausführung / construction: 20 mm Stereo-Potentiometer

Welle / shaft: \varnothing 4 oder 6 mm, L = 50 mm

Buchse / bushing: M7 x 0,75 / M10 x 0,75

Drehbereich / rotation angle: 300° eff. 267°



Lebensdauer / operation life: 20.000 Zyklen / cycles

Printausführung / for printed circuits (PC)

Drahtanschlussausführung / ordinary wiring (OW)

Conductive Plastic

PC2G20BU - OW2G20BU

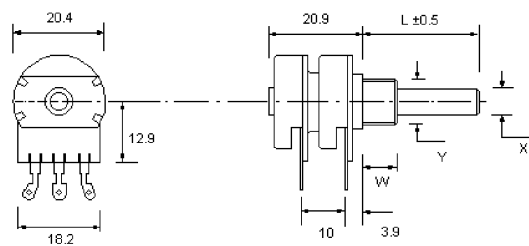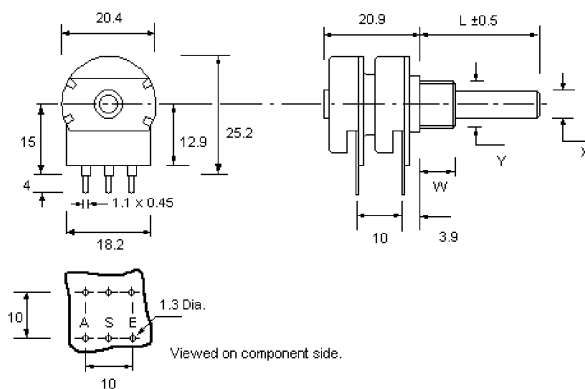

	4 mm Welle F21-PC			6 mm Welle F1-PC								
	lin.	poslog	neglog	lin.	poslog	neglog	lin.	poslog	neglog	lin.	poslog	neglog
100 R												
220 R												
470 R												
1 k												
2,2 k												
4,7 k				9904								
10 k				9905*	9918							
22 k				9906	9919							
47 k				9907*	9920							
100 k				9908*	9921							
220 k												
470 k												
1 M												
2,2 M												
4,7 M												
* lagermäßige Ausführungen (unverbindlich) \\ * in stock (non-binding)												