

5650000

wolfcraft®




40

EN 13743

max. 80 m/s
± 13.300 rpm



Ø
115 mm

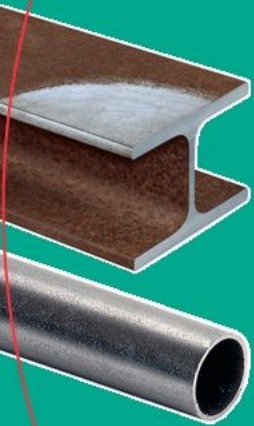

4 006885 565005

wolfcraft GmbH
Wolffstraße 1
56746 Kempenich
Germany
www.wolfcraft.com