


Data Sheet

TECHNICAL SPECIFICATIONS

Material:	Polyamid, UL-recognised	
Operating Temperature:	-55°C to +110°C	
Cable Entry:	Top	
Thumbscrews:	UNC 4-40 (Standard) M2,5 or M3 on request	
Cable O.D:	9-way	Up to 8mm
	15-way	Up to 11,7mm
	25-way	Up to 11,7mm
	37-way	Up to 11,7mm
Colour:	Black	

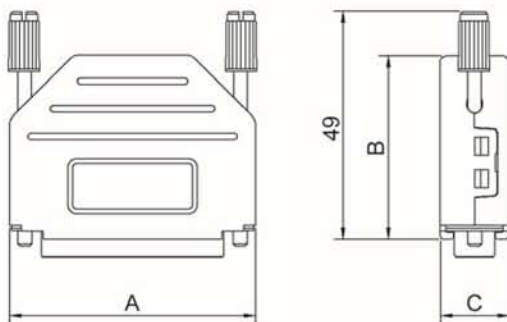

Size	Dim A	Dim B	Dim C
9-way	31,5	34,0	15,0
15-way	40,0	34,0	15,0
25-way	53,5	34,0	15,0
37-way	70,0	40,0	15,0