


Data Sheet

TECHNICAL SPECIFICATIONS


Material:	Zinc, Nickel Plated
Operating Temperature:	-25°C to +90°C
Cable Entry:	90° Side Entry
Jackscrews:	UNC 4-40, M3 on request
Cable O.D:	9-way: Up to 8,1mm 15-way: Up to 8,1mm 25-way: Up to 11,4mm 37-way: Up to 16,5mm 50-way: Up to 16,5mm
Type of grommets:	Compression Inserts



Compression Insert Sizes:
(inner diameter)

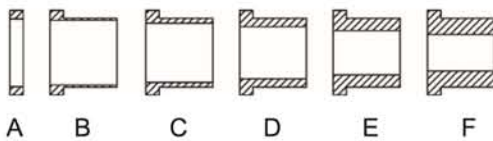

Size	A	B	C	D	E	F
9/15	8,10	8,00	7,25	6,50	5,30	-
25	11,40	10,40	9,40	7,60	5,80	-
37/50	16,50	15,75	14,50	12,70	10,80	8,90

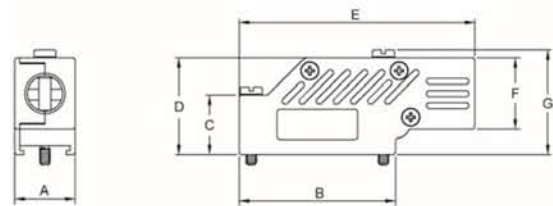

Size	A	B	C	D	E	F	G
9	15,0	30,8	15,0	24,4	50,8	18,0	26,2
15	15,2	39,4	15,0	24,4	59,3	18,0	26,4
25	15,8	53,3	23,1	34,5	72,4	24,3	35,0
37	15,8	69,9	23,1	40,9	89,7	30,7	42,9
50	18,0	67,1	-	40,9	86,9	30,7	42,9