

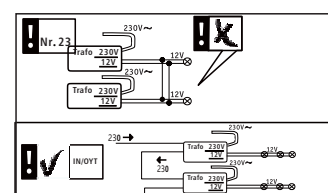
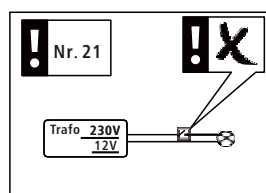
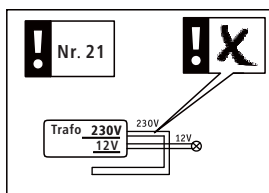
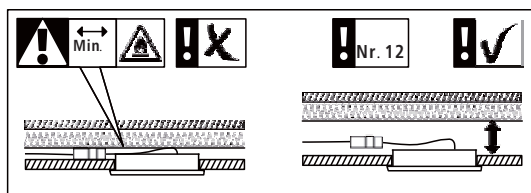
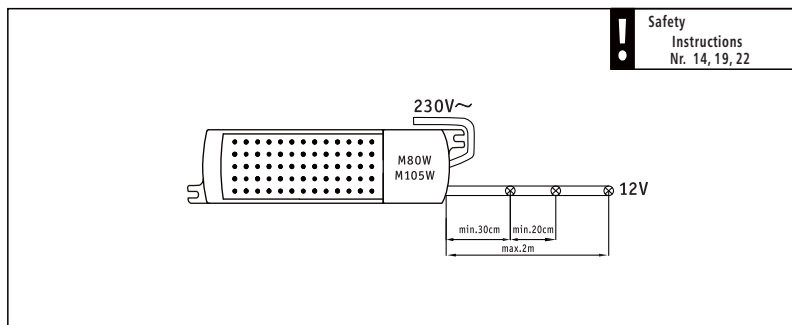
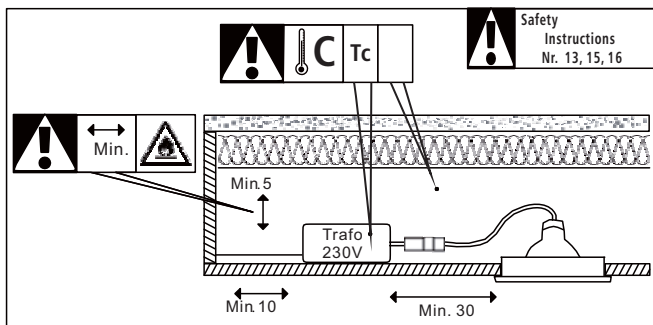
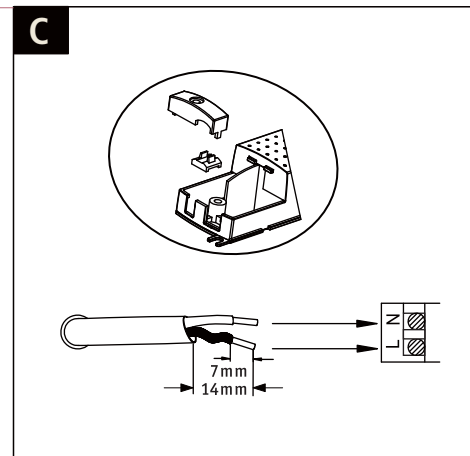
 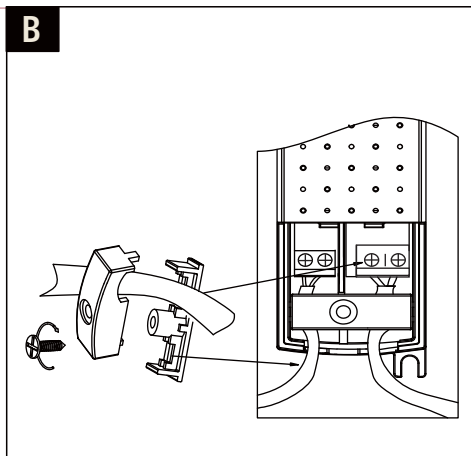
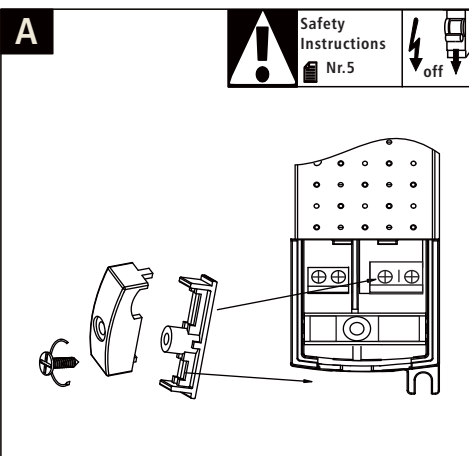




Art.-Nr.: 977.53
977.54

(+MA 197) PDG 10/16

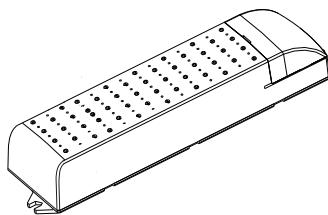

Trafo 80/105VA Art.-Nr.: 977.53 977.54	Safety Instructions Nr. 28a/b	R, L, C	80VATC: +75°C 105VATC: +80°C	Ta -20 +50°C
12V 230V	230V PRI	12V SEC	☒ H03VVH2-F ☒ H05VVH2-F ☒ NYM3 × 2.5mm²	min. 2x0,75mm²
			min. H03VVH2-F 1.0mm² X2	min. 2x0,75mm²