

10pcs Grease filled Splice Butt Connector Set



Item No. 1905C137(Transparent)

1905C138 (Blue)


1905C139 (Green)

Feature:

- Self-Stripping
- Moisture resistant
- Waterproof
- 4 Wire-contact

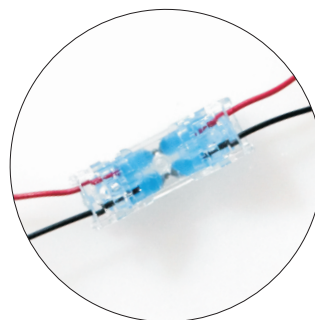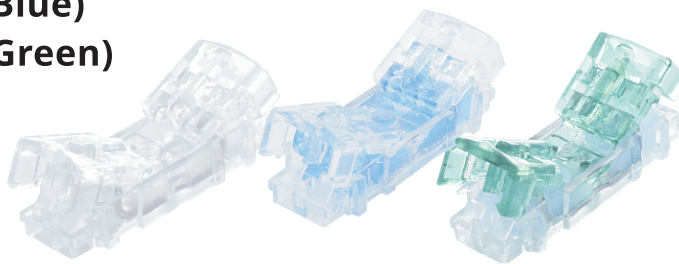

Dimension

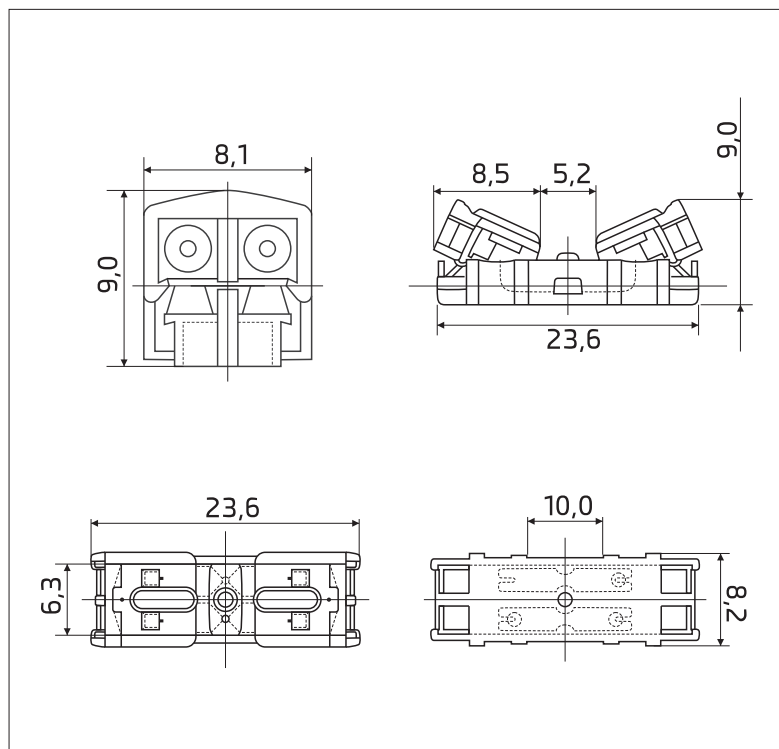

Specification

Insulation material: PC

Contact material: Tinned Brass

Color: Transparent / Blue / Green

Wire range: AWG 26 - 21 (0.4-0.7mm²)

Wire outer diameter: 1,4 mm (max.)

Conductor diameter: 0,4 ~ 0,7 mm

Voltage rating: 50V/AC, 75V/DC max.

Current rating: 3A max.

Working temperature: 0-90°C

Working humidity: 95% RH

Package qty.: 10pcs