


15pcs Grease filled Drop Wire Lock Joint Connector Set

Item No. 1905C130



Feature:

- Self-Stripping
- Moisture resistant
- Waterproof
- 2 Wire U-contact

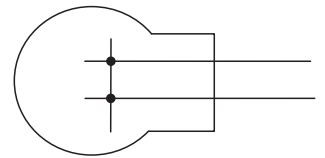

Specification

Insulation material: PC

Contact material: Tinned Brass

Color: Yellow cap / Transparent base

Wire range: AWG 26 -21 (0.4-0.9mm²)

Wire outer diameter: 1,52 mm (max.)

Conductor diameter: 0,4 ~ 0,7 mm

Voltage rating: 50V/AC, 75V/DC max.

Current rating: 3A max

Working temperature: 0-90°C

Working humidity: 95% RH

Package qty.: 15pcs

Dimension

