

 

10pcs Grease filled Drop Wire Splice Butt Connector Set

Item No. 1905C136



Feature:

- Self-Stripping
- Moisture resistant
- Waterproof
- 4 Wire-contact

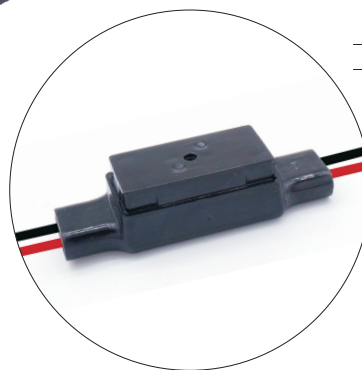

Specification

Insulation material: PC

Contact material: Tinned Brass

Color: Black

Wire range: AWG 19 - 16 (0.9-1.3mm²)

Wire outer diameter: 4,4 mm (max.)

Conductor diameter: 0,9 ~ 1,3 mm

Voltage rating: 50V/AC, 75V/DC max.

Current rating: 3A max.

Working temperature: 0-90°C

Working humidity: 95% RH

Package qty.: 10pcs

Dimension

