








---







**ENDURA® FLOOD**


---

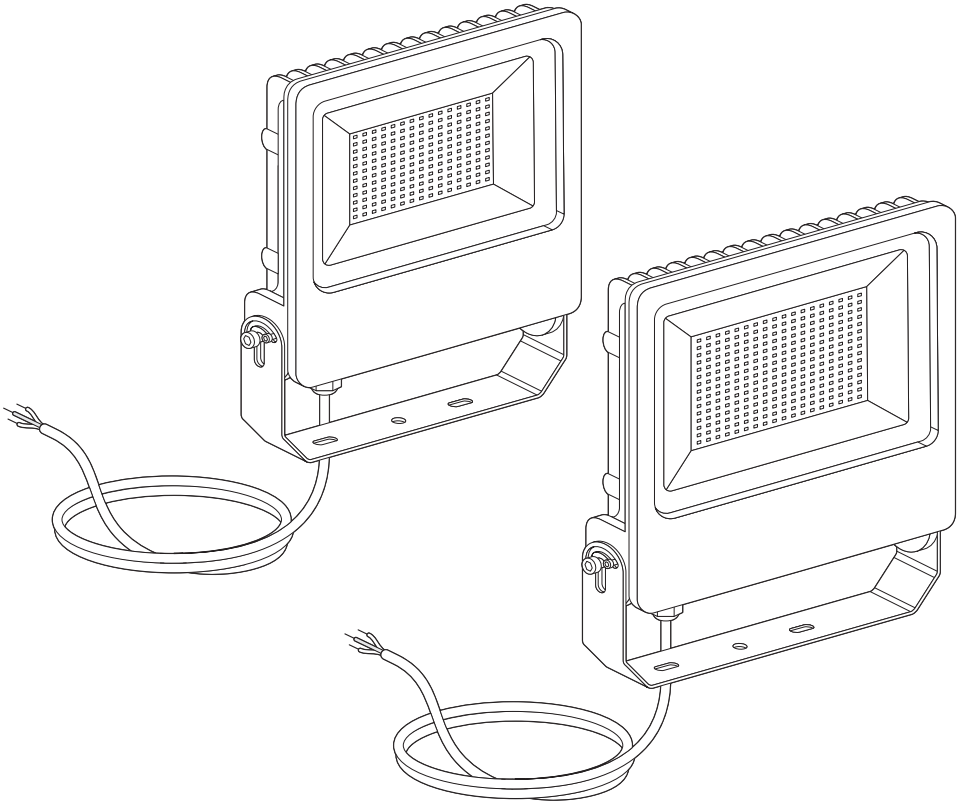

	EAN	W	lm	K	⊖ (°C)	V-	mA	Hz	PF
<b>ENDURA® FLOOD 100W 840 DG</b>	4058075206809	100	8800	4000	-20...+45	220-240	550	50/60	≥0.9
<b>ENDURA® FLOOD 150W 840 DG</b>	4058075206823	150	13200	4000	-20...+45	220-240	750	50/60	≥0.9

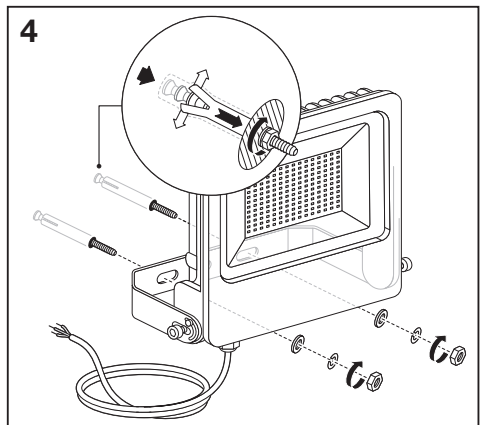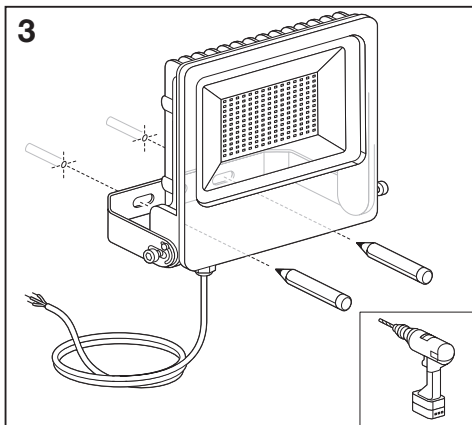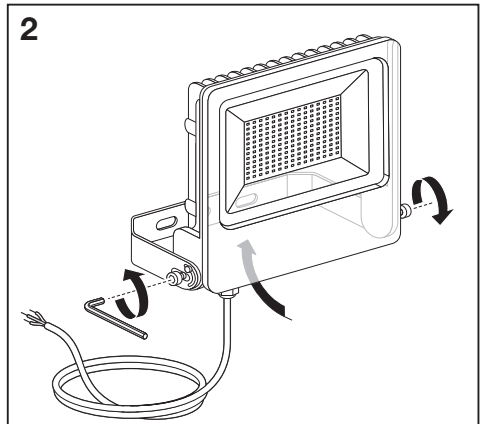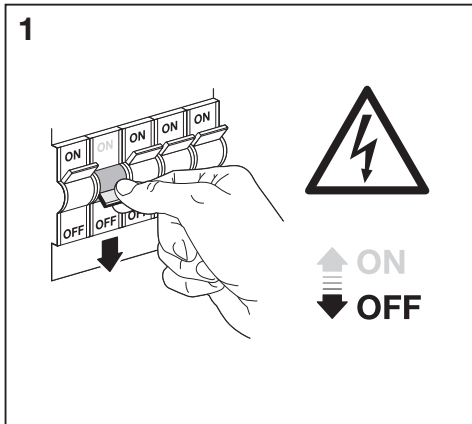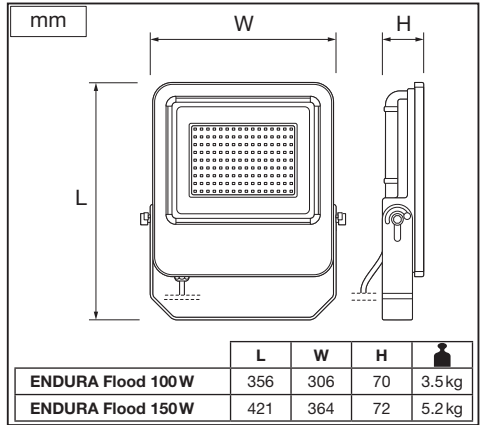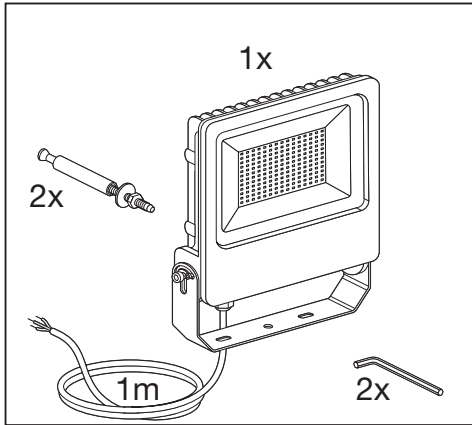

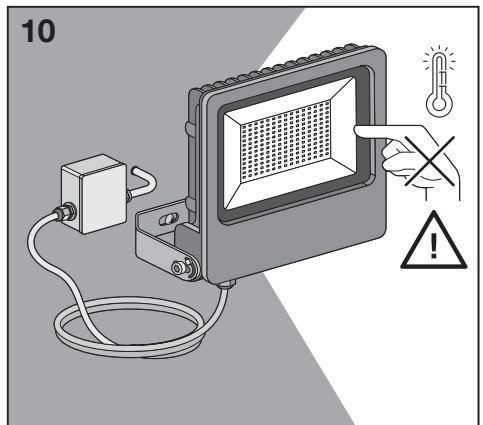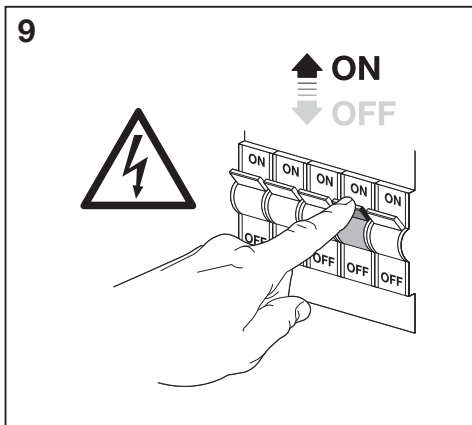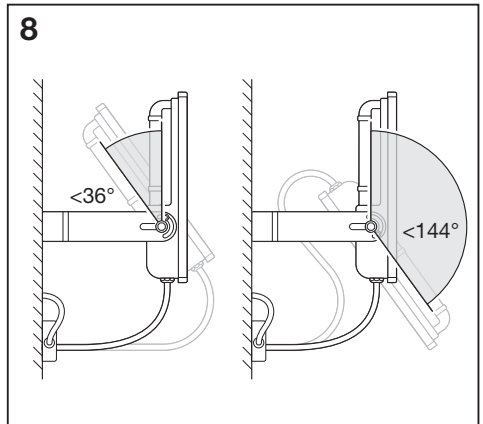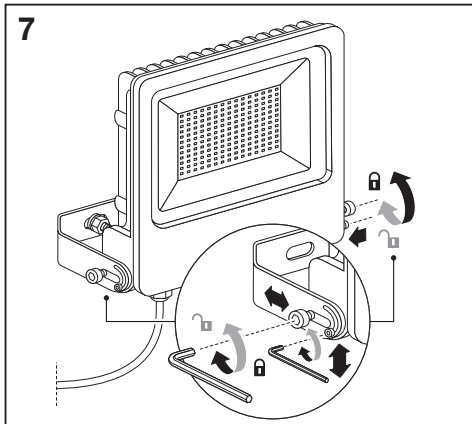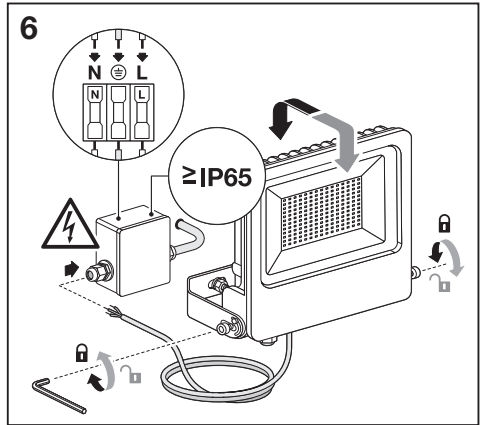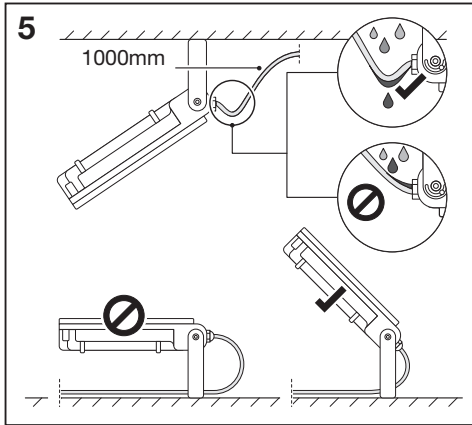



LEDVANCE GmbH  
Steinerne Furt 62  
86167 Augsburg, Germany  
[www.ledvance.com](http://www.ledvance.com)