



brennenstuhl®

SICHERHEITSINFORMATIONEN

SAFETY INFORMATION

DE	Sicherheitsinformationen	HU	Biztonsági információk	LT	Saugos informacija
EN	Safety information	RU	Информация о безопасности	LV	Drošības informācija
FR	Informations sur la sécurité	TR	Güvenlik bilgileri	HR	Sigurnosne informacije
NL	Veiligheidsinformatie	FI	Turvallisuustiedot	RO	Informații privind siguranța
IT	Informazioni sulla sicurezza	GR	Πληροφορίες για την ασφάλεια	BG	Информация за безопасност
SE	Säkerhetsinformation	PT	Informações de segurança	DK	Oplysninger om sikkerhed
ES	Información de seguridad	EE	Ohutusalane teave	NO	Sikkerhetsinformasjon
PL	Informacje dotyczące bezpieczeństwa	SK	Bezpečnostné informácie	UA	Інформація з техніки безпеки
CZ	Bezpečnostní informace	SI	Varnostne informacije	AR	معلومات السلامة

WWW.BRENNENSTUHL.COM

04/11/2024




Garant
GAR S 2425 R315 IP44 DE
25 m H05RR-F 3G1,5

IP44



— MAX 1000 W/230V~
— MAX 3300 W/230V~

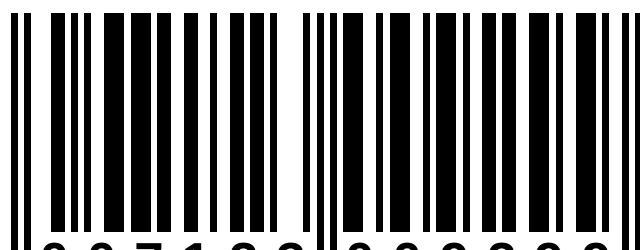

Art. 1 19852 0

0411685 • 4624 •

Made in Germany

4 0 0 7 1 2 3 0 0 9 2 9 9

service@brennenstuhl.com Hugo Brennenstuhl GmbH & Co. KG, Seestr.1-3, D-72074 Tübingen


DE Bei Überhitzung alle Stecker ziehen, nach Abkühlung Rückstellknopf drücken! Reparatur nur durch Elektro-Fachkraft. **FR** En cas de surchauffe, débrancher toutes les fiches. Après refroidissement, appuyer sur le bouton de remise en marche ! Réparation uniquement par un technicien qualifié.

SAFETY-SYSTEM



EN If overheating occurs, remove all the plugs from their sockets, after cooling down press the reset button! Repair only by qualified electrician. **NL** Bij oververhitting alle stekkers uittrekken en na afkoeling resetknop indrukken! Reparatie alleen door een gekwalificeerde elektricien.

0534304/4523

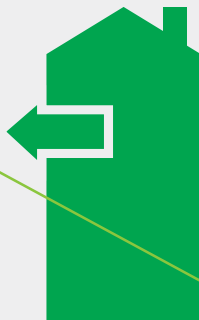

**Für den Einsatz im Innenbereich
und kurzfristig auch im Aussenbereich.**

**For use in dry conditions
and for temporary outside use.**

H05RR-F

0534295/4523