






Mini USB 2.0 Female Connector modular

Item No. 2001C207

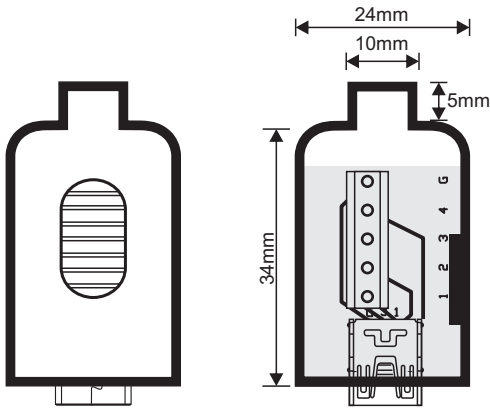

Screwdriver Included

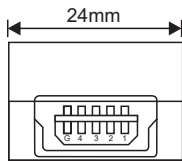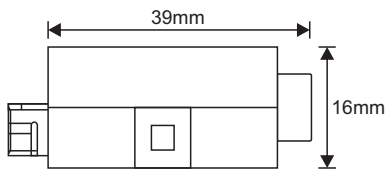

	1	2	3	4	5
	VBUS	D-	D+	ID	GND

Material:
 Housing: PP
 Insulator: PBT
 Connector shell: SPCC with plated Ni 40µ min.
 Contact: Brass with plated Au1µ
 Technical:
 Voltage rating: 30V max.
 Current rating: 1.0A max.
 Contact resistance: 500mΩ max.
 Insulation resistance: 100MΩ min.
 Dielectric withstanding voltage: 100V/AC(R.M.S)
 Operation temperature: -20 ~85°C