


## Specification / Spezifikation

Model-No / Modell Nr.	CD4315V24BRHWE
Dimension / Abmessungen	Ø 43 x 160 mm
Rated Voltage / Nennspannung	24VDC
Operating Voltage / Arbeitsspannung	16 ~ 26 VDC
Rated Current / Nennstrom	0,20 A +/- 18%
Power / Leistung	4,8 W
Rotating Speed / Umdrehungen	2500 rpm +/- 10%
Airflow / Luftdurchsatz	71,36 m <sup>3</sup> /h
Static Pressure / Statischer Druck	1,2 mm H <sub>2</sub> O
Noise Level / Geräusch	37 dBA
Weight / Gewicht	270 g
Material / Material	Aluminium
Bearing / Lager	Ball Bearing / Kugellager
Connection / Anschluss	2 wire / 2 Anschlusslitzen red/rot (+) / black/schwarz (-)

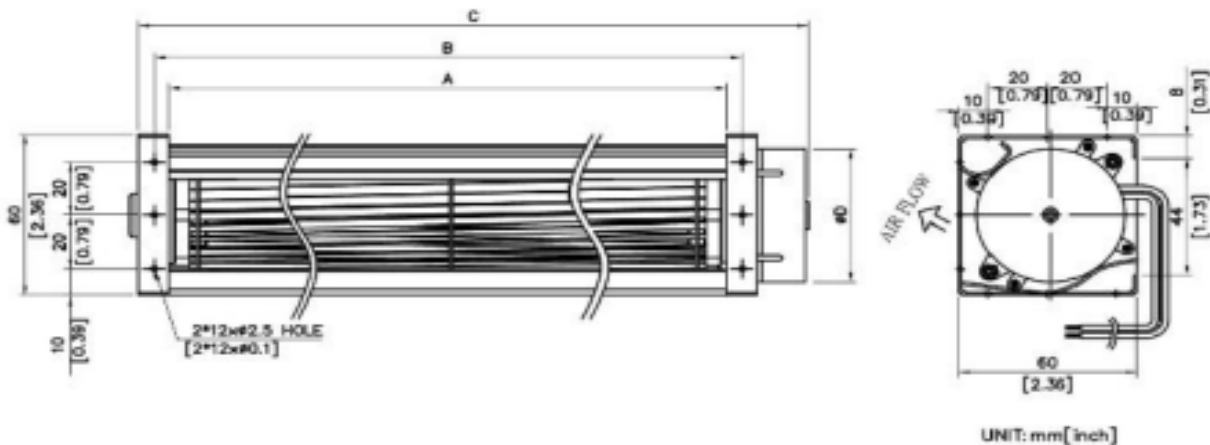

A = 160 mm   B = 170 mm   C = 208 mm   D = 38 mm

Irrtum und Druckfehler vorbehalten / Errors and Omissions excepted