

Safety Instructions

1, 2, 3, 4, 5, 6, 7, 10, 12, 13, 14, 15, 16,
17, 18, 19, 20, 21, 22, 24, 28, 33, 34



Info

www.paulmann.com

Paulmann Licht GmbH
Quezinger Feld 2
31832 Springe
Germany

www.paulmann.com

Art.-Nr.: 942.92

942.93

942.94

942.95

942.96

942.97

942.98

942.99

943.00

943.01

943.02

943.03

 
943.04

943.05

943.06



942.92_942.94_942.96



1x

 


1x




2x

943.06



1x

 942.93_942.95_942.97



3x



3x

 


6x




2x


942.98_943.00
943.02_943.04



1x

 


1x

 


2x

 942.99_943.01
943.03_943.05




3x

 


3x



6x

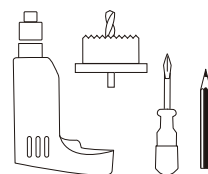

(+MA326) PSPU 01/20

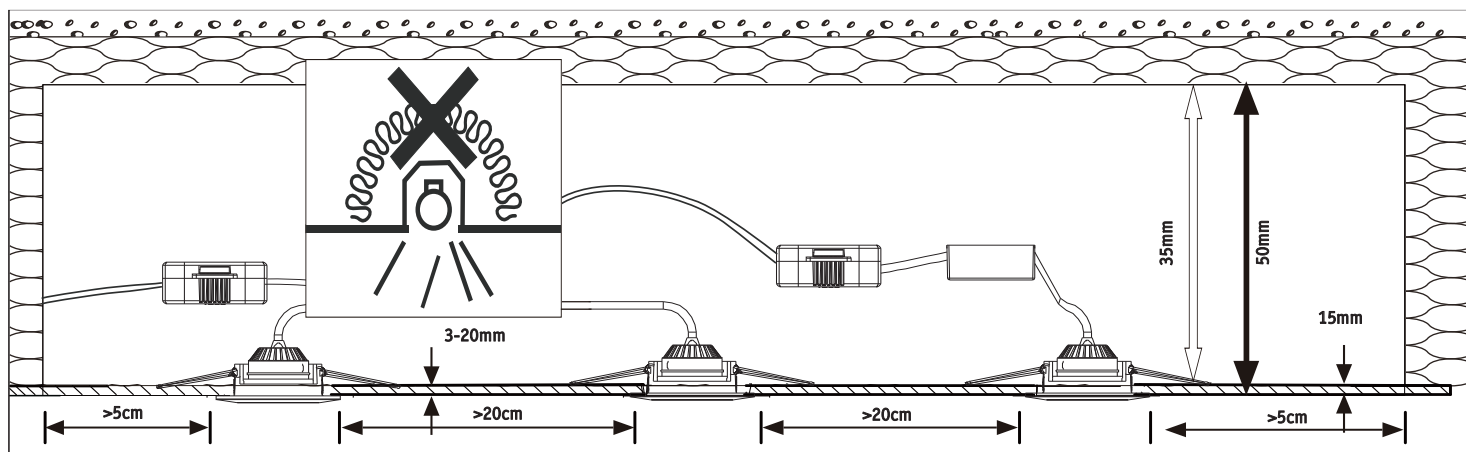


942.92_942.93
942.94_942.95
942.96_942.97




⇒IP20

 
942.98_942.99
943.00_943.01
943.02_943.03
943.04_943.05



⇒IP20

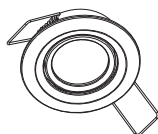


⇒IP23

 


⇒IP44

942.92_942.93
942.94_942.95
942.96_942.97

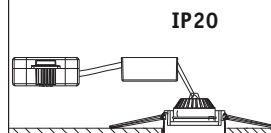

IP23

942.98_942.99_943.00
943.01_943.02_943.03
943.04_943.05

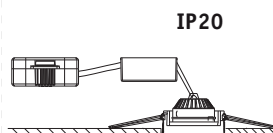

IP44

A


Ø x mm

Safety Instructions
 Nr. 1, 4, 5, 7

off

item number **hole size**

942.92_942.93 942.94_942.95	Ø54mm
942.96_942.97	Ø55mm
942.98_942.99 943.00_943.01 943.02_943.03 943.04_943.05	Ø54mm

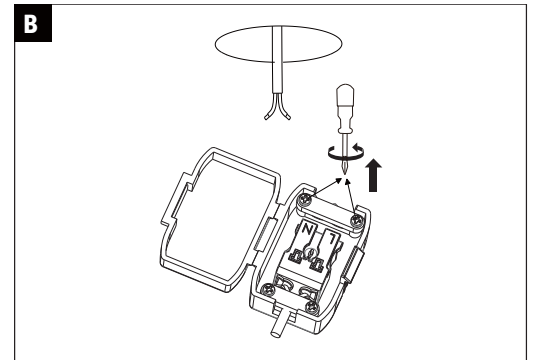

C


a.

Ø8-12mm 7mm 14mm

230V~


b.

230V~

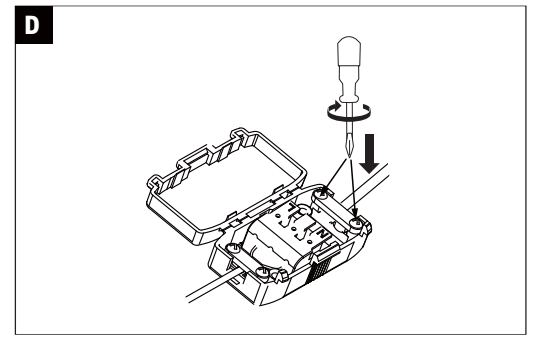

E

230V~

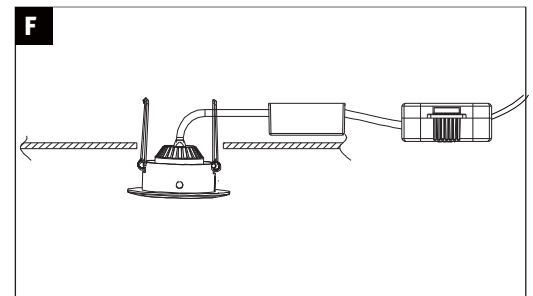

i

!X

!✓ OK

! on

15°

942.92_942.93
942.94_942.95
942.96_942.97

! on

942.98_942.99
943.00_943.01
943.02_943.03
943.04_943.05

ENERGY Y IJA
 энергия · ενεργεια
 IE IA

A++
A+
A
B
C
D
E

4 kWh/1000h

300 lm
4 W
230 V

warm white
2700K

CRI/Ra ≥ 80

ON OFF **>50.000**

Lumen 60% **<1 s**

Ø35 mm

≈30x 1.000h

CE

390094306