



Paulmann

Safety Instructions

1, 4, 7, 8, 33, 34



Info

www.paulmann.com

Paulmann Licht GmbH
Quezinger Feld 2
31832 Springe
Germany

www.paulmann.com

Art.-Nr.: **999.76**

(+MA 326)PE0 10/20



Bottom cell




1x




2x




A

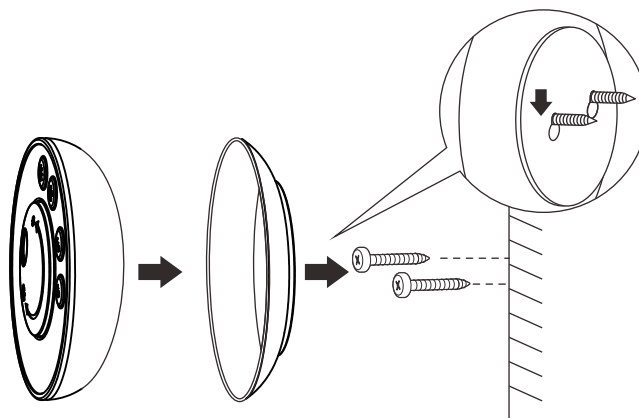



B

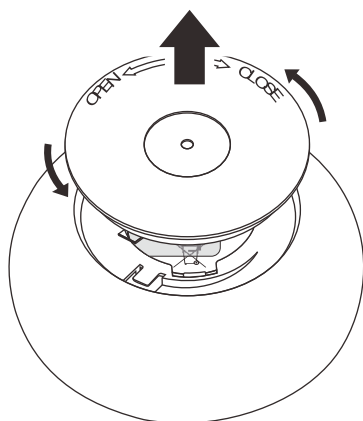

C

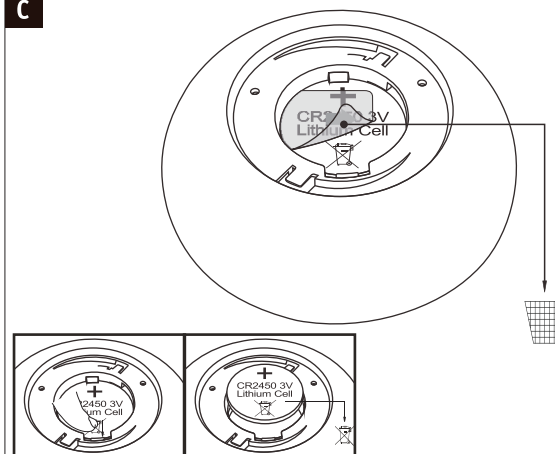


D

 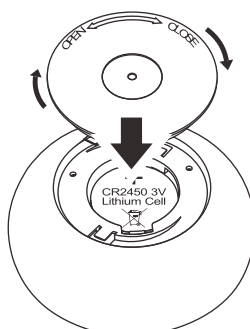


 **only use un-rechargeable 1x Button cells CR2450 3V,600mA;**

Function of keys

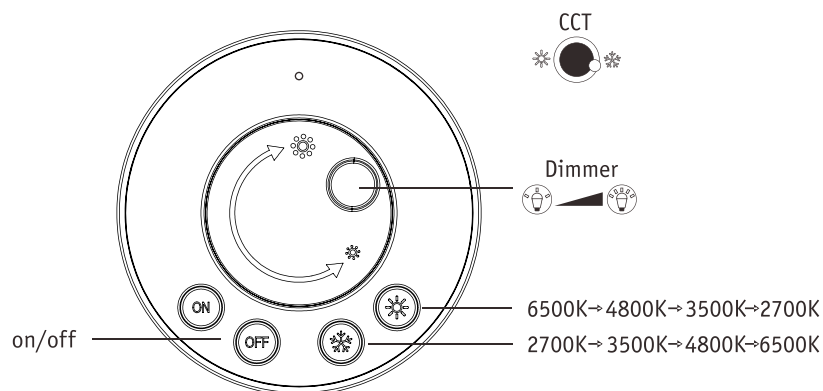

Code Matching


(Press the "ON" button one time within 5s of connecting to the controller)

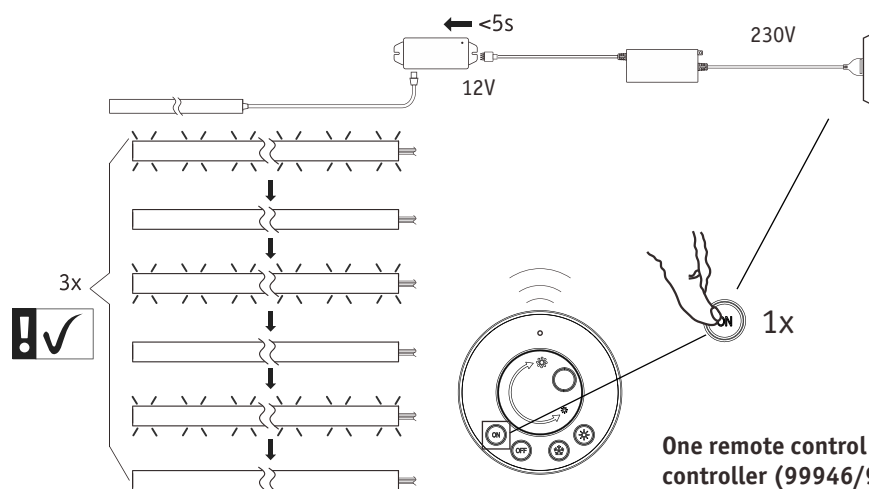

One remote control can control countless controller (99946/99947/99948), but a controller (99946/99947/ 99948) can be only controlled by 4 pcs remote control.

Code Clearing

(Press the "NO" button three times within 5s of cancelling the connection to the controller)

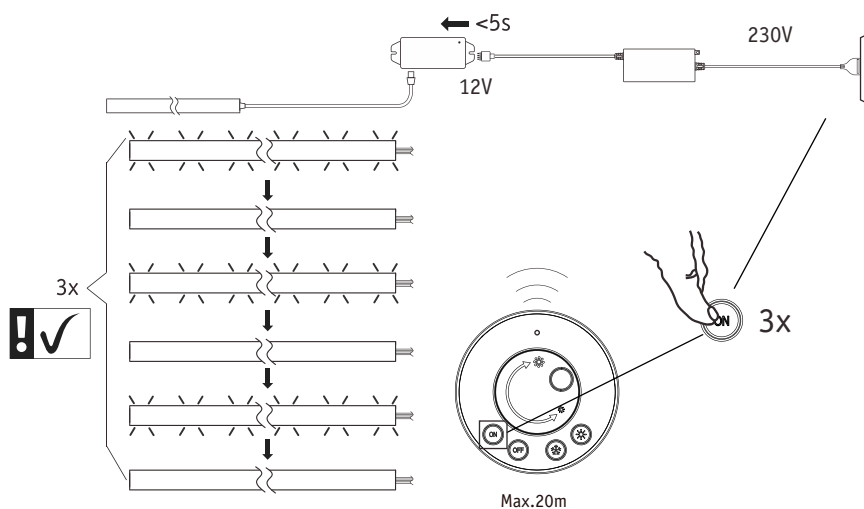

Hiermit erklärt Paulmann Licht, dass der Funkanlagentyp Art.-Nr.: 999.76 der Richtlinie 2014/53/EU entspricht. Der vollständige

Text der EU-Konformitätserklärung ist unter der folgenden Internetadresse verfügbar: www.paulmann.de

Zugelassen für den Betrieb in allen Ländern der EU / Approved for operating in all European countries

CE: Konform mit / in accordance with / conformément a 2014/30/EU, 2014/53/EU <http://www.paulmann.com/ce>

Funk-Frequenz :2.4GHz -2.4835GHz Abgestrahlte Energie :10mW NO

Doesn't apply for the geographical area within a radius of 20km from the centre on "Ny Alesund"