

Safety Instructions

1, 2, 3, 4, 5, 6, 7, 10, 12, 13, 14, 15, 16,
17, 18, 19, 20, 21, 22, 24, 28, 33, 34



Info

www.paulmann.com


Paulmann Licht GmbH
Quezinger Feld 2
31832 Springe
Germany

www.paulmann.com


Art.-Nr.: 942.92
942.93
942.94
942.95
942.96
942.97
942.98
942.99
943.00
943.01
943.02
943.03
943.04
943.05
943.06



942.92_942.94_942.96

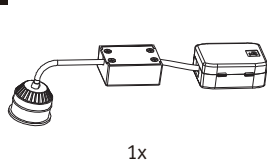

1x

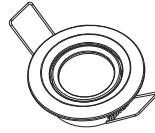


1x



2x


943.06

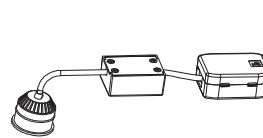


1x



942.93_942.95_942.97

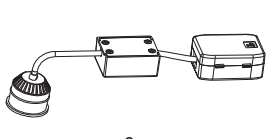

3x

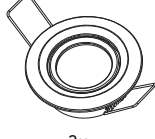


3x




6x




2x

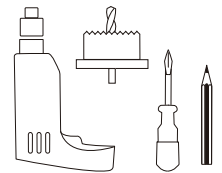

942.98_943.00
943.02_943.04

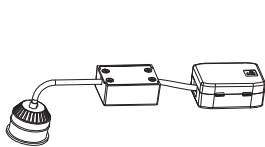


1x

 


1x

942.99_943.01
943.03_943.05

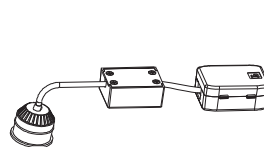


3x

 

3x




 2x




6x



(+MA326) PSPU 01/20

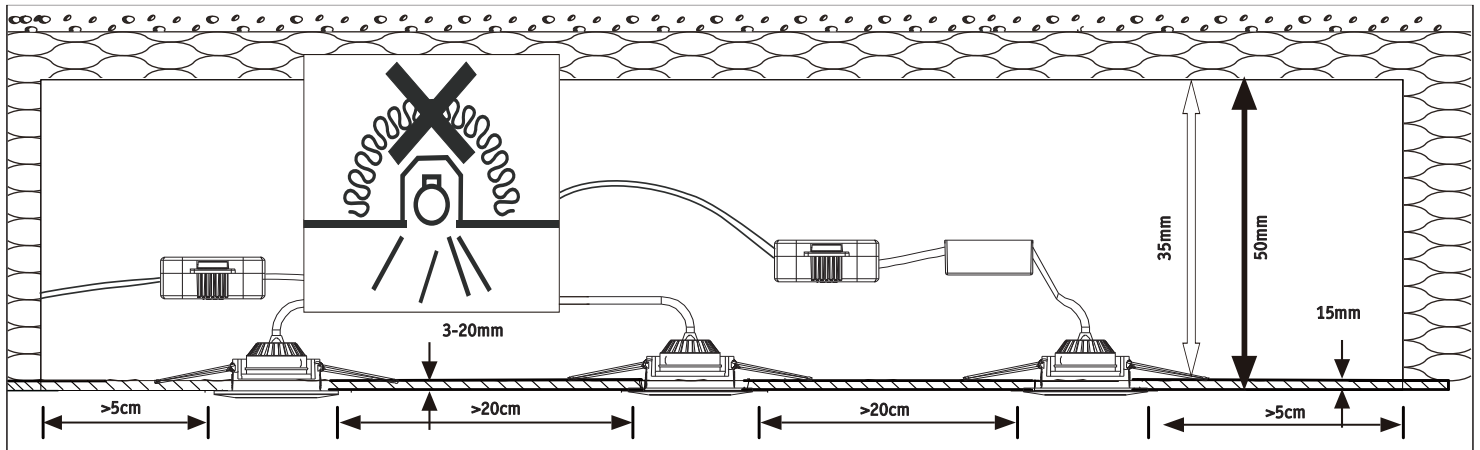

 
942.92_942.93
942.94_942.95
942.96_942.97



  942.98_942.99
943.00_943.01
943.02_943.03
943.04_943.05




942.92_942.93
942.94_942.95
942.96_942.97

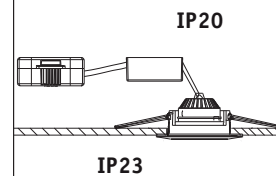

IP23

942.98_942.99_943.00
943.01_943.02_943.03
943.04_943.05

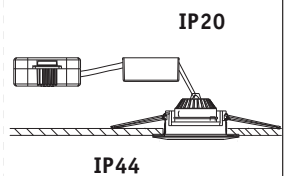


IP44

A

Safety Instructions
 Nr. 1, 4, 5, 7 off

item number	hole size
942.92_942.93 942.94_942.95	ø54mm
942.96_942.97	ø55mm
942.98_942.99 943.00_943.01 943.02_943.03 943.04_943.05	ø54mm

ø x mm

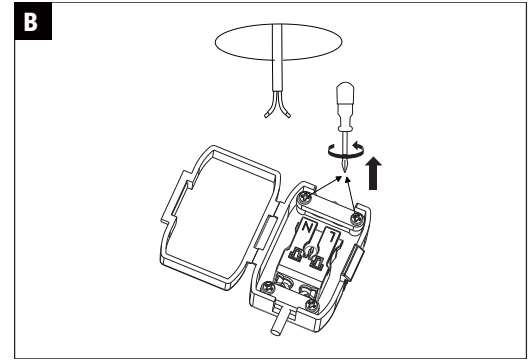


C

a.

b.

Safety Instructions
 Nr. 3, 4, 5, 6


230V~

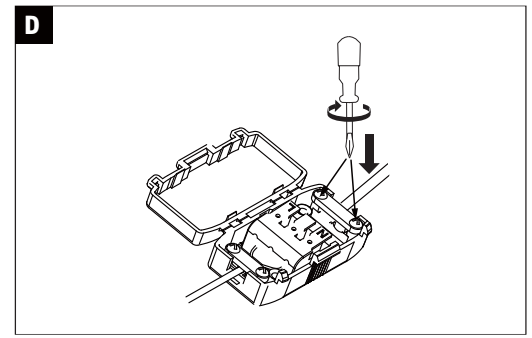

E

Safety Instructions
 Nr. 3, 4, 5, 6

230V~

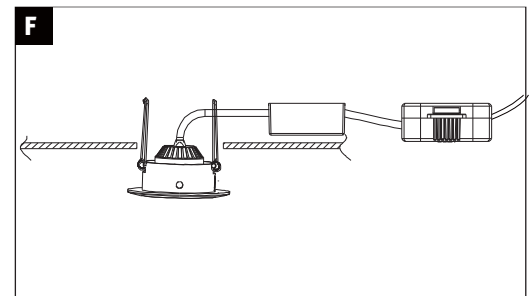

Safety Instructions
 Nr. 3, 4, 5, 6

230V~

Safety Instructions
 Nr. 3, 4, 5, 6

230V~

15°

942.92_942.93
 942.94_942.95
 942.96_942.97

Safety Instructions
 Nr. 3, 4, 5, 6

230V~

942.98_942.99
 943.00_943.01
 943.02_943.03
 943.04_943.05

ENERGY LABEL

Y IJA
IE IA

енергия · ενεργεια

A++
 A+
A+
 A
 B
 C
 D
 E

4 kWh/1000h

300 lm
 4 W
 230 V

warm white
 2700K

CRI/Ra ≥ 80

ON OFF >50.000

Lumen 60% <1 s

≈30x
 1.000h

ø35 mm

CE

PAP

390094306