

Safety Instructions

1, 2, 3, 4, 5, 6, 7, 10, 12, 13, 14, 15, 16,
17, 18, 19, 20, 21, 22, 24, 28, 33, 34



Info

www.paulmann.com

Paulmann Licht GmbH
Quezinger Feld 2
31832 Springe
Germany

www.paulmann.com

Art.-Nr.: 942.92

942.93

942.94

942.95

942.96

942.97

942.98

942.99

943.00

943.01

943.02

943.03

 
943.04

943.05


943.06



942.92_942.94_942.96



1x

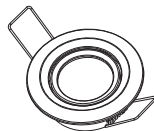


1x




2x

 943.06



1x

 942.93_942.95_942.97



3x



3x

 


6x




2x


942.98_943.00
943.02_943.04



1x

 


1x

 


2x

 942.99_943.01
943.03_943.05




3x

 


3x



6x

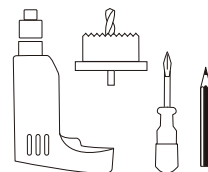




(+MA326) PSPU 01/20

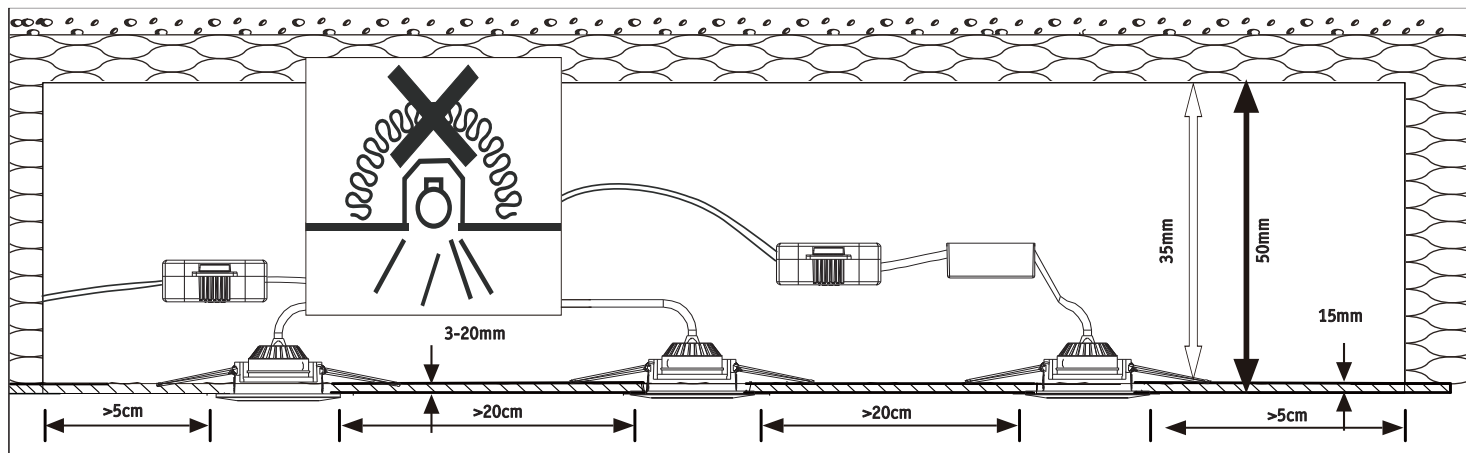

942.92_942.93
942.94_942.95
942.96_942.97




  942.98_942.99
943.00_943.01
943.02_943.03
943.04_943.05

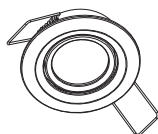

942.92_942.93
942.94_942.95
942.96_942.97

 
IP20



IP23

942.98_942.99_943.00
943.01_943.02_943.03
943.04_943.05

 IP20



IP44


A

Safety Instructions
 Nr. 1, 4, 5, 7

off

i

item number	hole size
942.92_942.93 942.94_942.95	Ø54mm
942.96_942.97	Ø55mm
942.98_942.99 943.00_943.01 943.02_943.03 943.04_943.05	Ø54mm

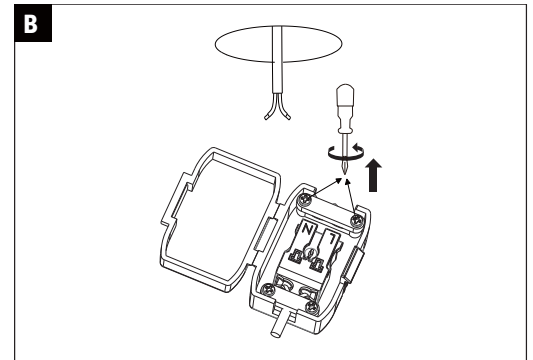


C

a.

230V~

b.

230V~

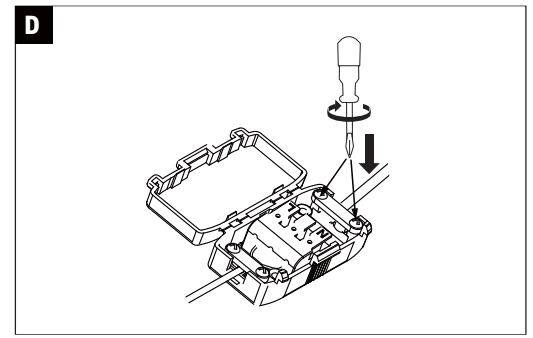


E

i

!X

!X

!X

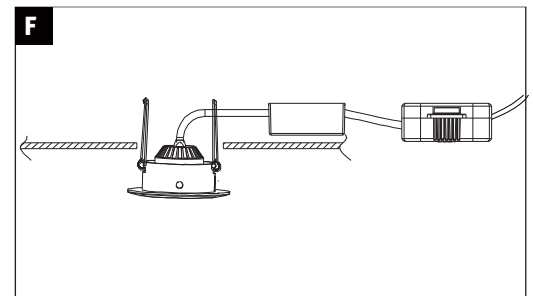

i

!X

!X

!X

OK

! on

15°

942.92_942.93
942.94_942.95
942.96_942.97

! on

942.98_942.99
943.00_943.01
943.02_943.03
943.04_943.05

ENERGY Y IJA
IE IA
 энергия · ενεργεια

A++
A+
A
B
C
D
E

A+

4 kWh/1000h

Ø35 mm

300 lm
4 W
230 V

warm white
 2700K

CRI/Ra ≥ 80

ON OFF ≥50.000

Lumen 60% <1 s

≈30×
 1.000h

390094306