

# BUZZER

Buzzer AS 10.00 knx




## Overview

- Buzzer for building automation KNX
- Up to 3 input objects can be configured
- Adjustable volume level (soft, medium, loud)
- Adjustable sequence
- Clearly structured ETS
- Easy handling and mounting
- Various mounting capabilities
- Compact housing

## Order numbers

■ müller	
AS 10.00 knx	Buzzer

## Accessories

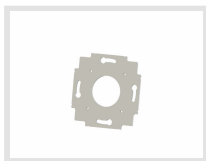

Mounting plate for wall box



Mounting angle

# BUZZER

## Buzzer AS 10.00 knx

### Technical data

Supply voltage	via KNX bus voltage
Bus current	< 12 mA
Bus system	KNX
Volume level	soft medium loud
Tone sequence	continuous tone or adjustable sequence
Permitted ambient temperature	-10...+45 °C
Housing	self-extinguishing thermoplastic
Housing color	studio white (similar to RAL 9016) specific colors on request
Mounting	wall mounting in frame (55x55) wall mounting with mounting angle
Type of connection	push-in connector
Type of protection	according to DIN EN 60529: IP X1 IP X4 when mounted with mounting angle
Class of protection	III when installed according to regulations

Rights to technical amendments reserved / Technische Änderungen vorbehalten  
Droits de modifications techniques réservés / Suscettibile di errori e modifiche

