



LS 20.00 pro4



Manual

LS 20.00 pro4

cs	da	de	el
en	es	fr	it
nl	no	sv	



Technical data

Type of battery	CR 2032 life time approx. 6 years
Lux range	1 ... 65.000 Lux
Lux range for sun protection	5.000 ... 65.000 Lux
Temperature range	0 ... 45°C
Rel. humidity range	0 ... 100%
Transmission type	Bluetooth 4.2
Range	75 m
Ambient temperature	-10°C ... 45°C
Dimensions	55 x 55 x 11,5 mm
Type of protection	According to DIN EN 60529: IP X1 IP X4 for wall mounting with mounting angle

Intended Use

The device can be used in following applications:
Sun protection with blind control, heating control, ventilation control etc.

Functionality

- the mi.sensor sends the current value every 2 minutes to the connected *mi.puck* system

Bestimmungsgemäße Verwendung




Das Gerät kann in folgenden Anwendungen eingesetzt werden:
Sonnenschutzfunktion durch Steuerung Von Rollläden, Heizungssteuerung, Lüftungssteuerung etc

Funktionsweise

- der mi.sensor sendet alle 2 Minuten den aktuellen Messwert an den verbundenen *mi.puck* system

Initial Operation

cs Uvedení do provozu da Første idriftsættelse de Erstinbetriebnahme el Εκκίνηση λειτουργίας es Funcionamiento inicial
fr Mise en service it Impostazioni iniziali nl Eerste inbedrijfstelling no Første igangsetting sv Inledande inställningar

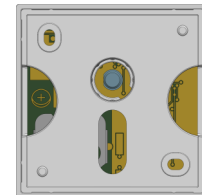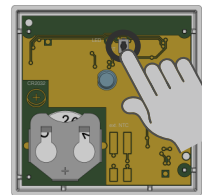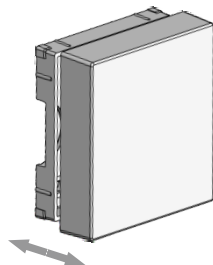

Operating Mode

cs Operační mód da Enheds type de Betriebsart el Τρόπος λειτουργίας es Tipo de dispositivo fr Type d'appareil
it Impostazioni iniziali nl Eerste inbedrijfstelling no Første igangsetting sv Inledande inställningar

Shutter / Blind timer

cs Časovač závěry da Skodder tidsstyring de Rolladen Timer
el Χρονοδιακόπτης για παντζούρι es Temporizador de persiana
fr Minuteur volet roulant it Tempo di scatto
nl Timer voor rolluiken no Lukkertid sv Slutartimer



Clock thermostat

es | Hodinový termostat | da | Termostat klokke | de | Uhrenthermostat
 el | Ρολοί θερμοστάτη | es | Termostato de reloj | fr | Horloge thermostat
 it | Orologio del termostato | nl | Klokthermostaat | no | Klokkestermostat
 sv | Slutartimer



Hygrostat

cs | Hygrostat | da | Hygrostat | de | Hygrostat | el | Υγρομετρητής
 es | Higrostat | fr | Hygrostat | it | Igrostato | nl | Hygrostaat
 no | Hygrostat | sv | Hygrostat

