


Sicherungsmuttern

DIN 979

Niedrige Sechskant-Kronenmutter

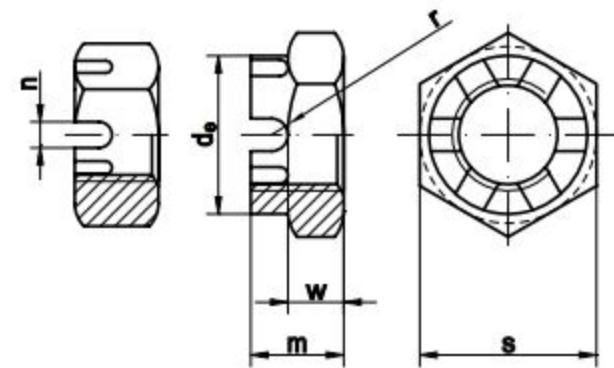

≤ M 10 ≥ M 12

Maße	M 16	M 18	M 20	M 24	M 30	M 36	M 42	M 48	M 52
$d_{e \max.}$	22	25	28	34	42	50	58	65	70
m	13	15	16	19	24	29	33	36	38
$n_{\min.}$	4,5	4,5	4,5	5,5	7	7	9	9	9
s	24	27	30	36	46	55	65	75	80
$w_{\max.}$	7	9	10	11	15	20	22	24	26
Splint	4x28	4x32	4x36	5x40	6,3x50	6,3x63	8x71	8x80	8x90