


Data Sheet

Push button switch

Version 12/22

The shaded part is illuminated

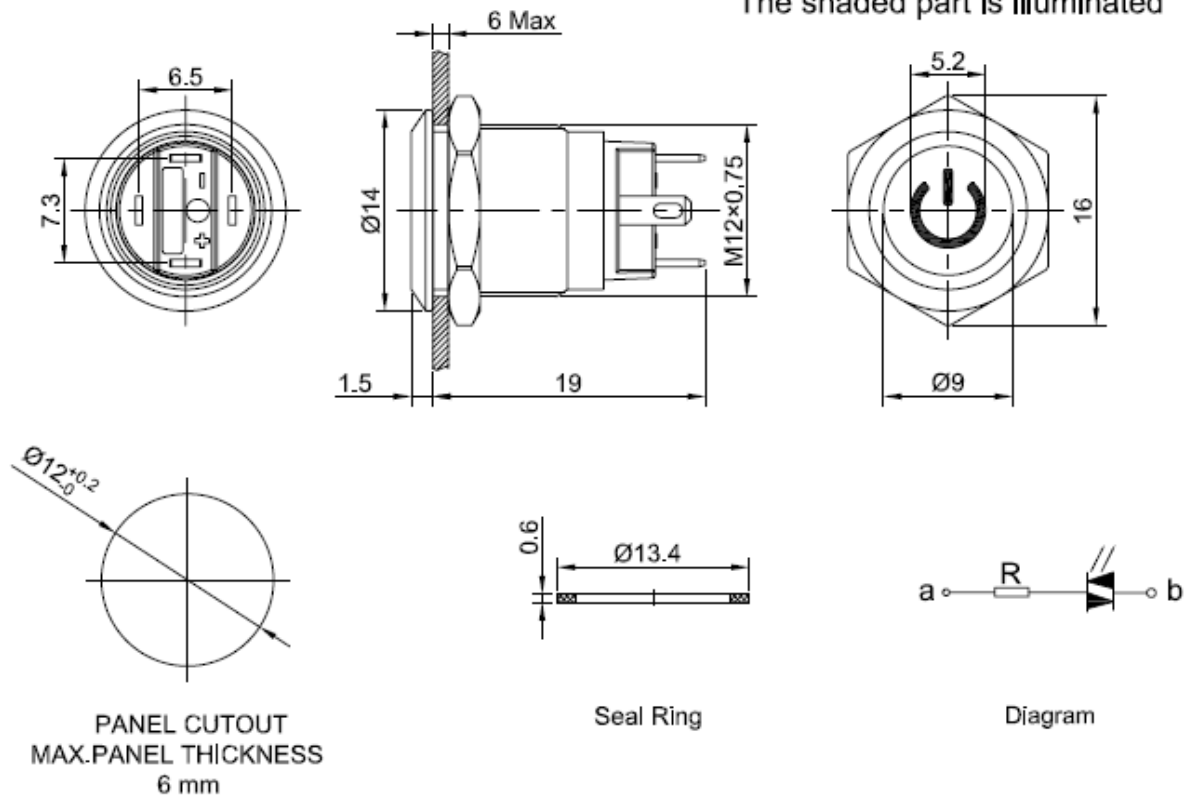

Specification

Mounting diameter	12mm
Head shape	Round head
Operation type	Momentary
Contact structure	1NO
Switch rating	2A/48VAC
Illumination type	Power symbol
LED	RGB 12V(external resistor 820Ω to the C pin)
Housing	Stainless steel
Terminal	Soldering Pins
Operating and storage temperature	-25 to +55 °C
Operating and storage humidity	45 to 85 % RH
IP rating	IP67