




NEEDED TO START (EXCL.)

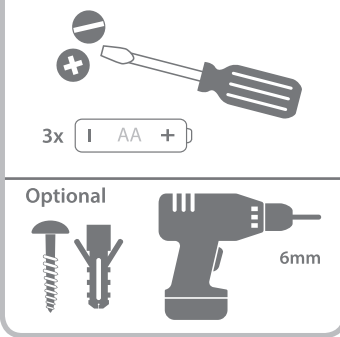


BOX CONTENT | INHALT | CONTENUS | INHOUD DOOS | CONTENUTO | CONTENIDO DE LA CAJA

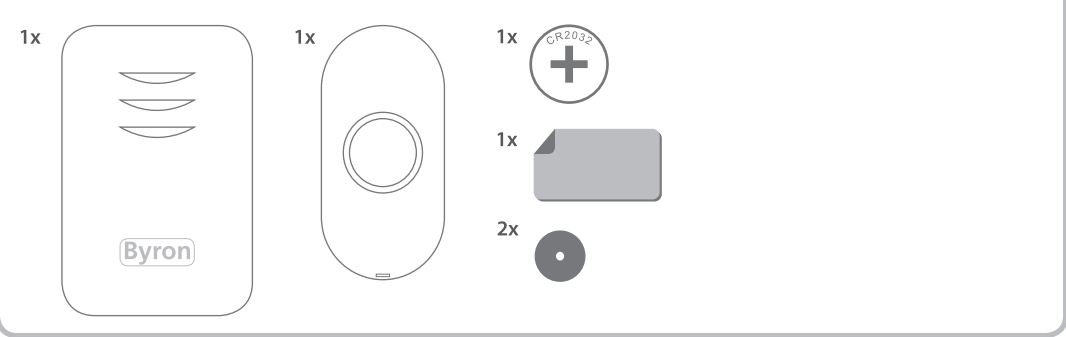


FIRST SET-UP | ERSTEINRICHTUNG | PREMIÈRE CONFIGURATION | EERSTE INSTALLATIE | PRIMO SET-UP | PRIMERA CONFIGURACIÓN

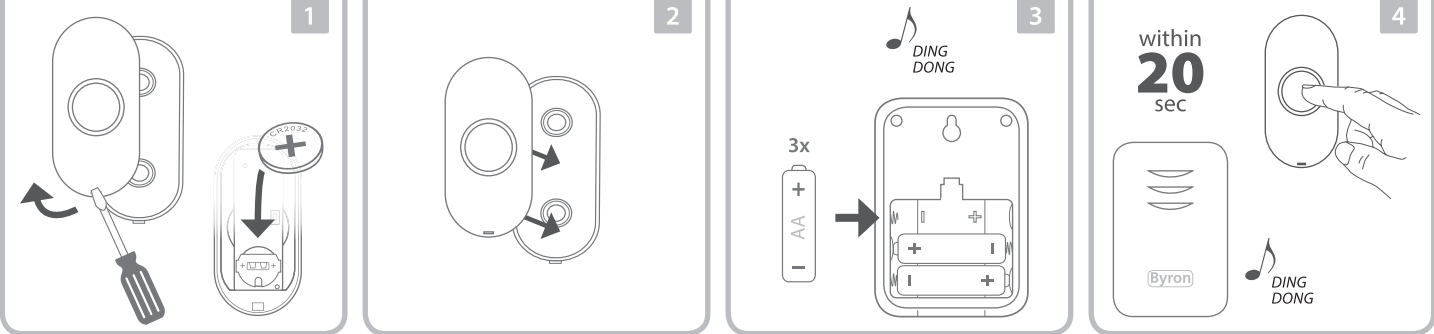


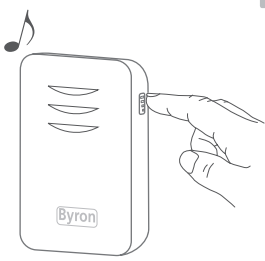
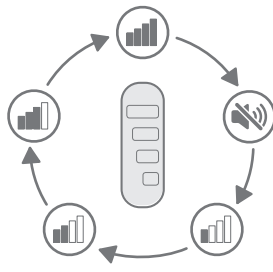

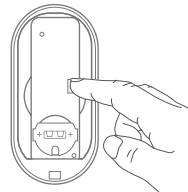
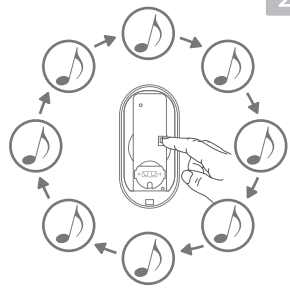
INSTALLATION | INSTALLATION | INSTALLATION | INSTALLATIE | INSTALLAZIONE | INSTALACIÓN

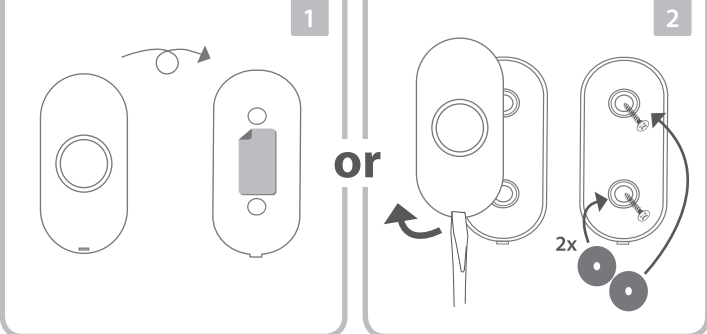



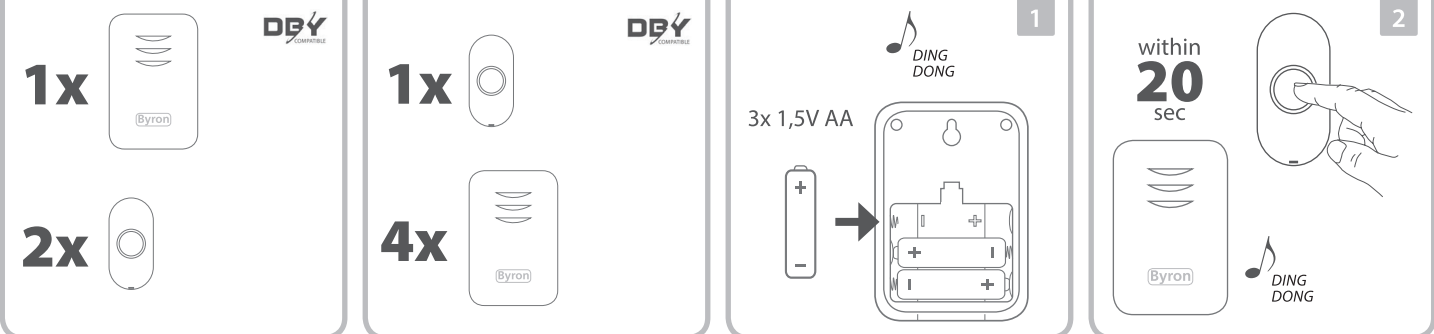


PAIRING MULTIPLE CHIMES | KOPPELEN MEHRERER KLINGELN | JUMELAGE DE PLUSIEURS CARILLONS | MEERDERE DEURBELLEN KOPPELEN | ACCOPPIAMENTO MULTIPO | EMPAREJANDO MÚLTIPLES TIMBRES




FEATURES | EIGENSCHAFTEN | CARACTÉRISTIQUES | KENMERKEN | CARATTERISTICHE | CARACTERÍSTICAS

	<p>1</p> 	<p>2</p> 
<p>16</p> 	<p>1</p> 	<p>2</p> 

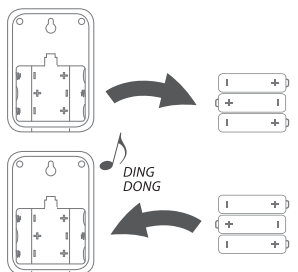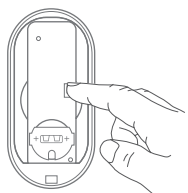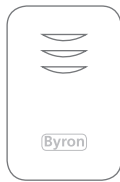TROUBLESHOOTING | FEHLERBEHEBUNG | RÉOLUTION DE PROBLÈMES | PROBLEMEN OPLOSSEN | RISOLUZIONE DEI PROBLEMI | SOLUCIÓN DE PROBLEMAS

<p><b>RESET</b></p> <p>1</p> 	<p>2</p>  <p>within 20 sec.</p> 	<p>3</p> <p>FIRST SET-UP   ERSTEINRICHTUNG   PREMIÈRE CONFIGURATION   EERSTE INSTALLATIE   PRIMO SET-UP   PRIMERA CONFIGURACIÓN</p> 	
--	--	--	---

WWW.CHBYRON.EU

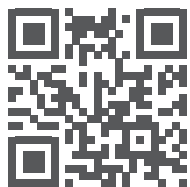

Find us on



Or contact us directly:

<p><b>smartwares</b> Europe</p> <p>Jules Verneweg 87 5015 BH Tilburg The Netherlands</p> <p>www.chbyron.eu</p>	NL: 088 5940501	Lokaal tarief
	BE: 078 481094(NL)	Lokaal tarief
	BE: 078 481540(FR)	Tarif local
	FR: 0825 560 650	18ct/min
	DE: +49 (0) 1805 010762	14Ct./Min. dt. Festnetz, Mobil max. 42Ct./Min
	UK: +44 (0) 345 230 1231	
ES: +34 938427589		

CUSTOMER SERVICE



Conforms to all relevant European Directives.

Frequency band: 433.92MHz (433.050 - 434.790 MHz)  
Maximum radio-frequency power: +5.92dB  
Range: 150 meters

**Wireless Doorbell DBY-22311**  
Power: 3 x 'AA'/LR6 1.5V: Total 4.5V  
Indoor Use Only

**Push button - DBY-23510**  
Power supply: 1 x CR2032 3V  
IP44 Weather Resistant

