

Griffserie A3

Zusammensteckbare Rohrgriffe.

Werkstoff und Oberfläche:

Ausführung A:

Griffschenkel und Verbindungsprofile aus stranggepresstem Aluminium AlMgSi 0,5. Spannhülsen aus Edelstahl.

Griffschenkel mattglänzend eloxiert, Verbindungsprofile feingeschliffen und eloxiert. Griffausführung in verschiedenen Farbkombinationen.

Ausführung B:

Griffschenkel aus stranggepresstem Aluminium AlMgSi 0,5; mattglänzend schwarz eloxiert.

Verbindungsrohr $\varnothing 25 \times 2$ mm aus Edelstahl. Spannteile aus Edelstahl bzw. Aluminium.

Tragkraft:

min. 1.000 N.

Hinweis:

Beliebige Griffhöhen oder andere Farbkombinationen auf Anfrage.

Handle Series A3

Fit together tubular handles.

Material and surface:

Version A:

Handle shanks and connecting profiles of extruded aluminium AlMgSi 0.5. Clamping sleeves of stainless steel.

Handle shanks anodized with dull bright finish, connecting profiles fine ground and anodized. Handle finish in various colour combinations.

Version B:

Handle shanks of extruded aluminium AlMgSi 0.5; black anodized with dull bright finish.

Connection tube $\varnothing 25 \times 2$ mm of stainless steel, clamping parts of stainless steel or aluminium.

Stress resistance:




min. 1.000 N.

Note:


Other handle lengths or colour combinations on request.




Ausführung Technical Line siehe Seite 103. Version Technical Line look at page 103.

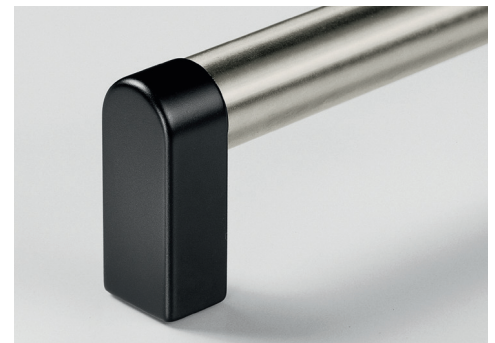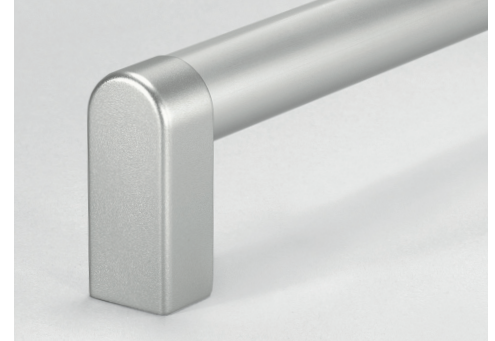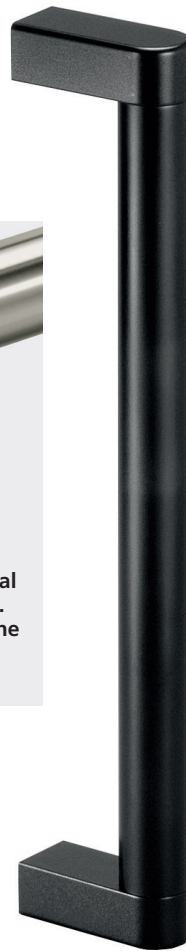

Ausführung A Version A

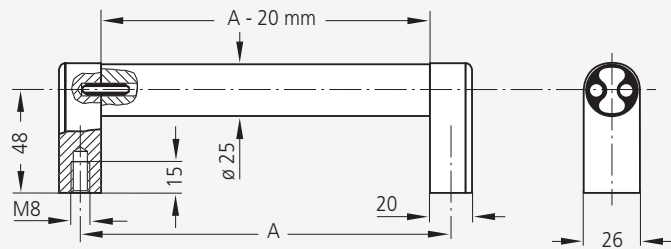

Ausführung B Rohr aus Edelstahl Version B Tube of stainless steel

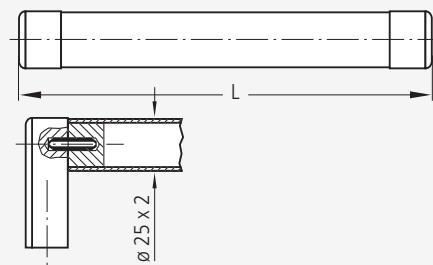

Griffsteg, Ausführung A Grip ledge, Version A

naturfarben / schwarz
natural colour / black

Griffsteg, Ausführung B Grip ledge, Version B

Rohr Edelstahl
Tube stainless steel

A	L	Schenkelfarbe Shank colour	Bestell-Nr. Order no.	Bestell-Nr. Order no.	Bestell-Nr. Order no.
200	220	natur / natural	A3-25.200.N01	A3-25.200.N04	–
		schwarz / black	A3-25.200.S01	A3-25.200.S04	A3-25.200.S37
250	270	natur / natural	A3-25.250.N01	A3-25.250.N04	–
		schwarz / black	A3-25.250.S01	A3-25.250.S04	A3-25.250.S37
300	320	natur / natural	A3-25.300.N01	A3-25.300.N04	–
		schwarz / black	A3-25.300.S01	A3-25.300.S04	A3-25.300.S37
400	420	natur / natural	A3-25.400.N01	A3-25.400.N04	–
		schwarz / black	A3-25.400.S01	A3-25.400.S04	A3-25.400.S37