



Paulmann

IP44



Info

 
www.paulmann.com

Paulmann Licht GmbH
Quezinger Feld 2
31832 Springe
Germany


www.paulmann.com

Art.-Nr.: 180.12


PSE 07/19



1x

 

1x

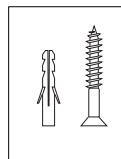


incl.




Ø 6mm




A

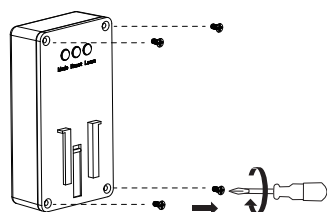


B

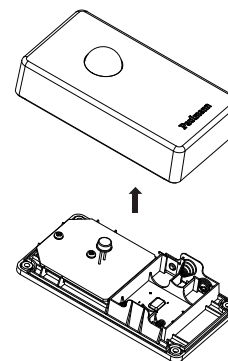


C

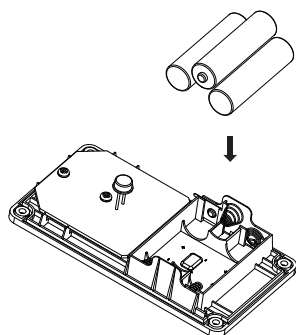


D

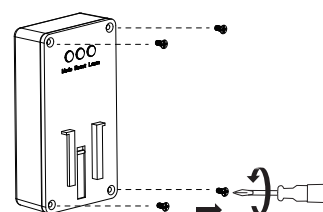


E

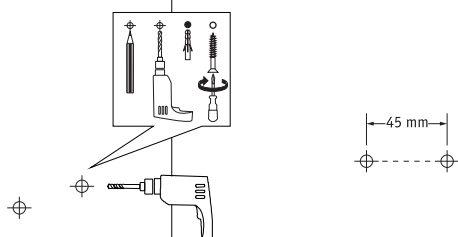


F

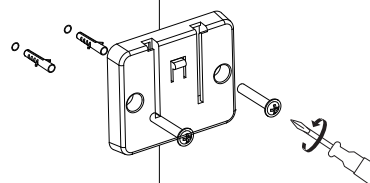

G

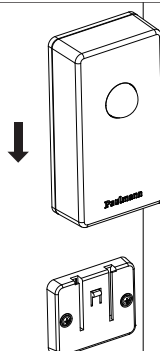

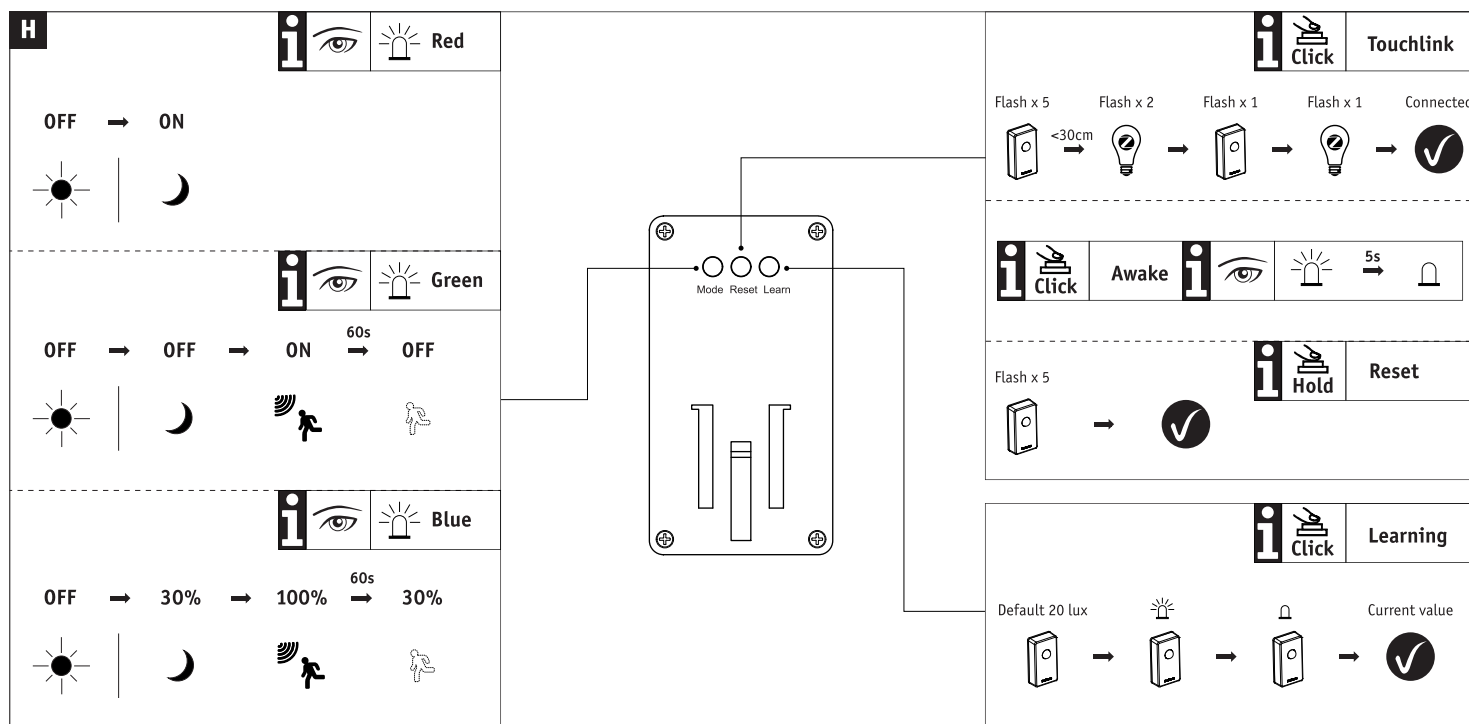

I

max. 15m
max. 20 end devices

not incl. Outdoor Plug & Shine ZigBee Controller

Paulmann
Art.-Nr.: **939.99**

Zugelassen für den Betrieb in allen Ländern der EU / Approved for operating in all European countries

CE: Konform mit / in accordance with /
conformement a 2014/30/EU, 2014/53/EU
<http://www.paulmann.com/de/de/b2b-haendler-log-in.html>

2,4 GHz -
2,4835 GHz

NO

doesn't apply for the geographical area within a radius of 20km from the centre on "Ny Alesund"

Hiermit erklärt Paulmann Licht, dass der Funkanlagentyp [180.12] der Richtlinie 2014/53/EU entspricht. Der vollständige Text der EU-Konformitätserklärung ist unter der folgenden Internetadresse verfügbar: " www.paulmann.com/ce "

Funk-Frequenz [2,4 GHz - 2,4835 GHz] Abgestrahlte Energie [10mW]