
 

 
 
 



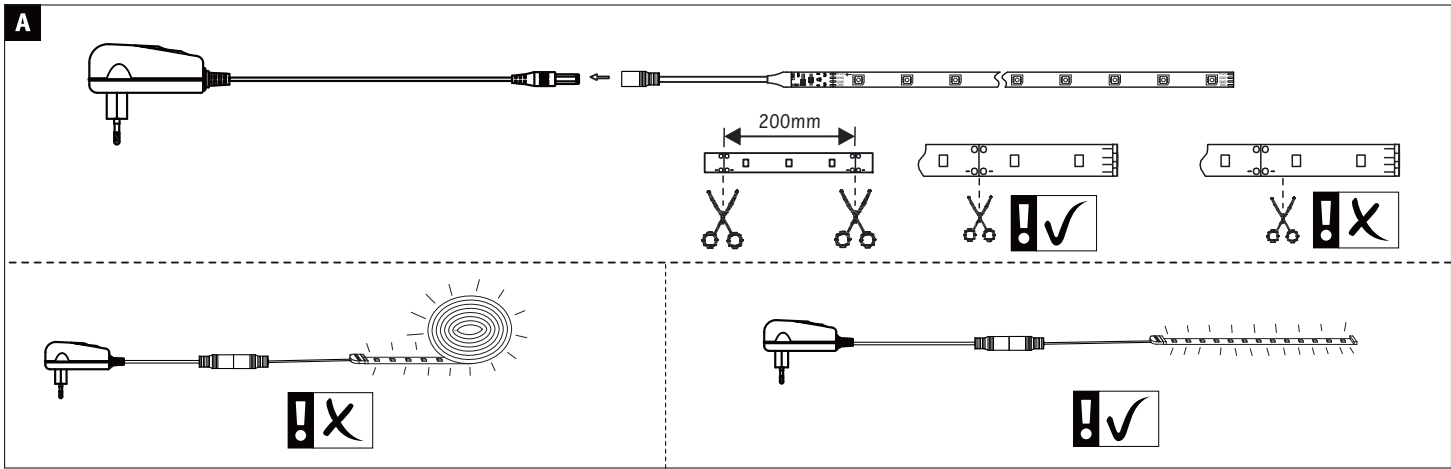
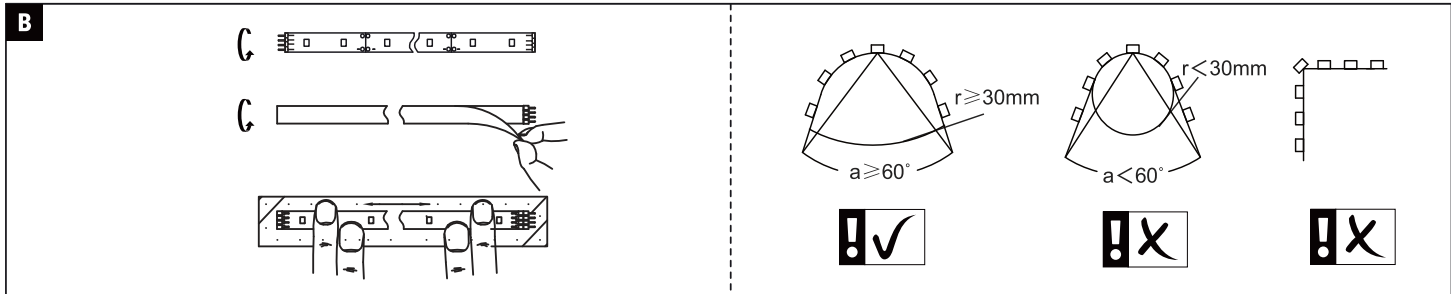


<p>Art.-Nr.: 705.13 705.14 705.15</p> <p>PLIR 04/19</p> <p>CE</p>	<p> 705.13: 5m</p> <p> 1x</p> <p> 1x</p> <p> 1x</p>	<p>705.14: 7.6m 705.15: 10m</p> <p> 1x</p> <p> 1x</p> <p> 1x</p> <p> 1x</p> <p></p>
---	--	---


A




B



C

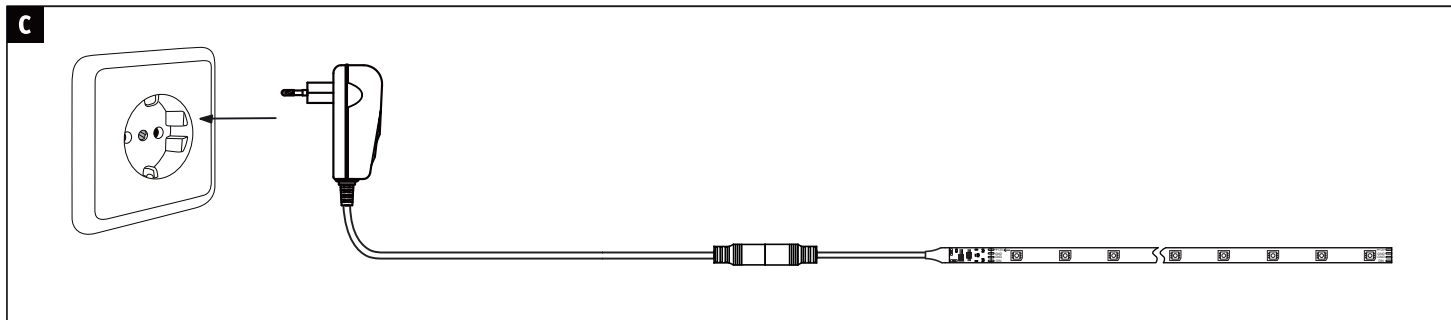

D

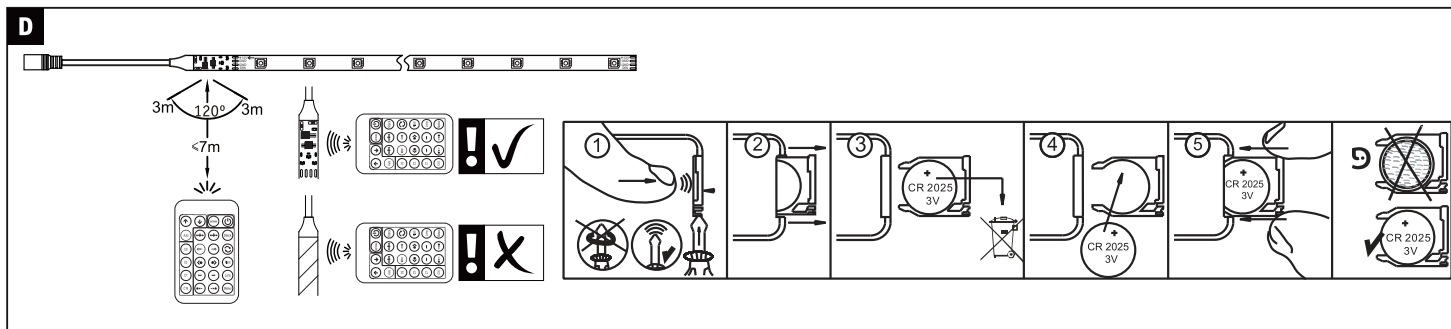



Paulmann




www.paulmann.com/manual-digled/all

- | | | | |
|---|---|---|--|
|  | Static Light effects:
dimming brightness up
Dynamic Light effects:
increases speed of light effect |  | Static Light effects:
dimming brightness down
Dynamic Light effects:
slows down speed of light effect |
|  | W/W/W shift key |  | ON/OFF key |
|  | Auto-cycle mode |  | flow to two terminals from centre
(CS,C3,C7,C16) |
|  | flow to centre from two terminals
(CS,C3,C7,C16) |  | IC number increasing cycle |
|  | eight-color choice key in static model |  | Trail into left (CS,C3,C7,C16) |
|  | Trail into right (CS,C3,C7,C16) |  | Trail from two directions in turn |
|  | three-color choice key in static model |  | Horse race to left direction (CS,C3,C7,C16) |
|  | Horse race to right direction (CS,C3,C7,C16) |  | Flash function key (CS,C3,C7,C16) |
|  | seven-color choice key in static model |  | spread to left (CS,C3,C7,C16) |
|  | spread to right (CS,C3,C7,C16) |  | Jump efficient key (CS,C3,C7,C16) |
|  | sixteen-color choice key in static model |  | Queued color running to left with a tag
(CS,C3,C7,C16) |
|  | Queued color running to right with a tag
(CS,C3,C7,C16) |  | Queued color running with a tag from two
directions in turn |

on / off

Dimm

 IC number increasing cycle

white / warm white

Light effects


Choose color


3 color

7 color


16 color

Mix of all effects

Mix of 

Fade 

Color jump

Mix of 

Speed