


Data Sheet

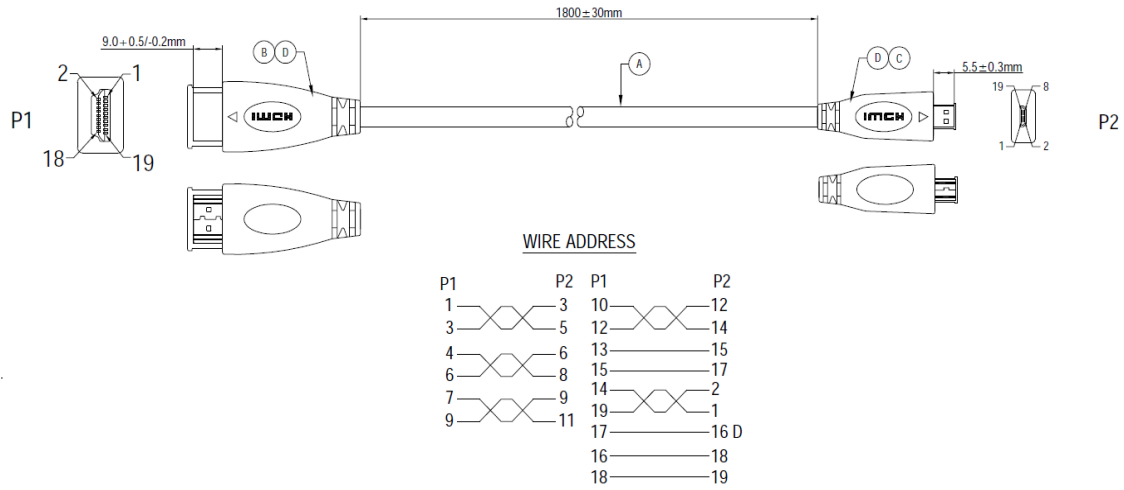

Electrical Test:

1. 100% TEST OPEN SHORT MIS-WIRE.
2. CONTACT RESISTANCE: 3Ω MAX.
3. INSULATION RESISTANCE: 5MΩ MIN.
4. HI-POT: 300V DC/10MS.
5. Real Test Passed 3840*2160P 60Hz.
6. Real Test Not Twinkling, Double Vision and Decolor.