

LED Arbeitsplatzleuchte LED workplace luminaire



CENALED SPOT DC, Flexarm

Artikelnr.: 121012-01

EAN: 4260556623719

Zolltarifnr.: 94054099

Bestellnr.: 121012-01

Modell: CENALED SPOT

Bauform: LED Arbeitsplatzleuchte mit Schwanenhals

Leuchtmittel: High Power LED

Lampenleistung: ~8,5 W

Lampenlichtstrom: 1120 lm

Lampenlichtausbeute: 134 lm/W

Lichtverteilung: direkt

Lichtfarbe: Neutralweiß (5000K)

Anschlusswert Leuchte: 24V DC \pm 10%

Betriebsgerät: -

Anschluss Leuchte: 3 m Anschlussleitung, Ölflex, mit offenen Leitungsenden

Schutzart: IP67

Schutzklasse: III

Abstrahlwinkel: 30°

Betriebstemperatur: -10... +50 °C

Farbwiedergabe (Ra): > 80

Lampenlebensdauer: > 60.000 h

Material Gehäuse: Aluminium (pulverlackiert)

Länge Flexarm [A]: 500 mm

Befestigung: Anschraubsockel

Gewicht: 800 g

Bruttogewicht: 1400 g


Risikogruppe: freie Gruppe

Befestigungszubehör: Magnethalterung optional

Dimmbar: ja, über Taster am Leuchtenkopf, Ein/Aus und Dimmen

Gefertigt in: Deutschland

Besonderheit: Universell einsetzbare Arbeitsleuchte mit hoher Schutzart

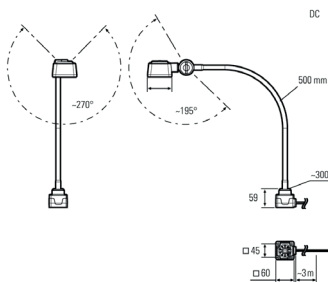

Lampenlebensdauer in Betriebsstunden (L80/B10)


LED Arbeitsplatzleuchte
LED workplace luminaire



CENALED SPOT DC, Flexarm

Item number:	121012-01
EAN:	4260556623719
Customs tariff number:	94054099

Order number:	121012-01
Model:	CENALED SPOT
Type:	LED workplace luminaire with gooseneck
Illuminant:	High Power LED
Power consumption:	~8,5 W
Lamp luminous flux:	1120 lm
Lamp luminous efficiency:	134 lm/W
Light distribution:	direct
Light colour:	neutral white (5000K)
Connected load:	24V DC \pm 10%
Power supply:	-
Connection (connector):	connection cable 3m, flexible, two open cable ends
Degree of protection:	IP67
Class of protection:	III
Beam angle (optics):	30°
Operating temperature:	-10... +50 °C
Colour rendering (Ra):	> 80
Lamps lifetime:	> 60,000 h
Housing material:	aluminium (powder finished)
Length Flexarm [A]:	500 mm
Mounting:	screw-on base
Weight (net):	800 g
Gross weight:	1400 g
Risk group (DIN EN 62471):	free group
Mounting accessories:	magnet holder plate optional
Dimmable:	yes, via push button at the luminaire head, ON/OFF and dimming
Made in:	Germany
Feature:	universal workplace luminaire with high protection degree

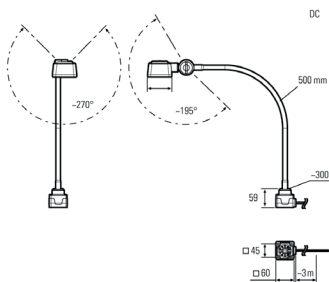

Lamps lifetime in operation hours (L80/B10)