

LED Arbeitsplatzleuchte


LED workplace luminaire



CENALED SPOT AC, Gelenkarm

Artikel-Nr.:	121012-12
EAN:	4260556623757
Zolltarifnr.:	94054099

Bestellnr.:	121012-02
Modell:	CENALED SPOT
Bauform:	LED Arbeitsplatzleuchte mit Gelenkarm
Leuchtmittel:	High Power LED
Lampenleistung:	~9 W
Lampenlichtstrom:	1120 lm
Lampenlichtausbeute:	134 lm/W
Lichtverteilung:	direkt
Lichtfarbe:	Neutralweiß (5000K)
Anschlusswert Leuchte:	100-305V AC \pm 10%, 50-60 Hz
Betriebsgerät:	integriert
Anschluss Leuchte:	3 m Geräteleitung mit Schutzkontaktstecker CEE 7/7
Schutzart:	IP65 / Kopf IP67
Schutzklasse:	I
Abstrahlwinkel:	30°
Betriebstemperatur:	-10... +50 °C
Farbwiedergabe (Ra):	> 80
Lampenlebensdauer:	> 60.000 h
Material Gehäuse:	Aluminium (pulverlackiert)
Material Abdeckung:	ESG 3,8 mm, sprungsicher
Länge Gelenkarme:	350 mm / 400 mm
Gewicht:	1400 g
Bruttogewicht:	2600 g
Risikogruppe:	freie Gruppe
Befestigungszubehör:	Magnethalterung optional
Dimmbar:	ja, über Taster am Leuchtenkopf, Ein/Aus und Dimmen
Gefertigt in:	Deutschland
Besonderheit:	Universell einsetzbare Gelenkarmleuchte mit hoher Schutzart

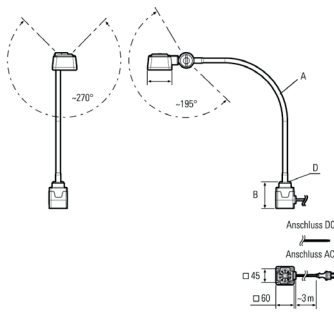

Lampenlebensdauer in Betriebsstunden (L80/B10)


LED Arbeitsplatzleuchte
LED workplace luminaire



CENALED SPOT AC, Gelenkarm (adjustable arm)

Item number:	121012-12
EAN:	4260556623757
Customs tariff number:	94054099

Order number:	121012-02
Model:	CENALED SPOT
Type:	LED workplace luminaire with adjustable arm
Illuminant:	High Power LED
Power consumption:	~9 W
Lamp luminous flux:	1120 lm
Lamp luminous efficiency:	134 lm/W
Light distribution:	direct
Light colour:	neutral white (5000K)
Connected load:	100-305V AC \pm 10%, 50-60 Hz
Power supply:	inbuilt
Connection (connector):	connection cable 3 m with SCHUKO plug CEE 7/7
Degree of protection:	IP65
Class of protection:	I
Beam angle (optics):	30°
Operating temperature:	-10... +50 °C
Colour rendering (Ra):	> 80
Lamps lifetime:	> 60,000 h
Housing material:	aluminium (powder finished)
Cover material:	ESG 3,8 mm, shatterproof
Length adjustable arms [A]:	350 mm / 400 mm
Weight (net):	1400 g
Gross weight:	2600 g
Risk group (DIN EN 62471):	free group
Mounting accessories:	magnet holder plate optional
Dimmable:	yes, via push button at the luminaire head, ON/OFF and dimming
Made in:	Germany
Feature:	universal workplace luminaire with adjustable arm and high protection degree

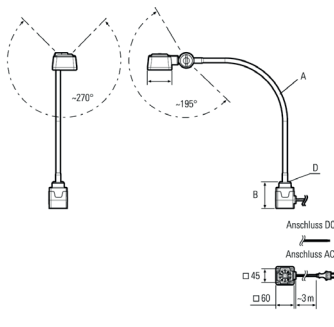

Lamps lifetime in operation hours (L80/B10)