


LED Maschinenleuchte
LED machine luminaire

CENALED SPOT DC, Gelenkkopf

Artikel-Nr.:	121012-03
EAN:	4260556623733
Zolltarifnr.:	94054099

Bestellnr.:	121012-03
Modell:	CENALED SPOT
Bauform:	LED Gelenkkopfleuchte
Leuchtmittel:	High Power LED
Lampenleistung:	~8,5 W
Lampenlichtstrom:	1120 lm
Lampenlichtausbeute:	134 lm/W
Lichtverteilung:	direkt
Lichtfarbe:	Neutralweiß (5000K)
Anschlusswert Leuchte:	24V DC \pm 10%
Betriebsgerät:	-
Anschluss Leuchte:	3 m Anschlussleitung, Ölflex, mit offenen Leitungsenden
Schutzart:	IP67
Schutzklasse:	III
Abstrahlwinkel:	30°
Betriebstemperatur:	-10... +50 °C
Farbwiedergabe (Ra):	> 80
Lampenlebensdauer:	> 60.000 h
Material Gehäuse:	Aluminium (pulverlackiert)
Material Abdeckung:	ESG 3,8 mm, sprungsicher
Gewicht:	400 g
Bruttogewicht:	550 g
Risikogruppe:	freie Gruppe
Befestigungszubehör:	Magnethalterung optional
Dimmbar:	ja, über Taster am Leuchtenkopf, Ein/Aus und Dimmen
Gefertigt in:	Deutschland
Besonderheit:	Universell einsetzbare LED Leuchte mit hoher Schutzart

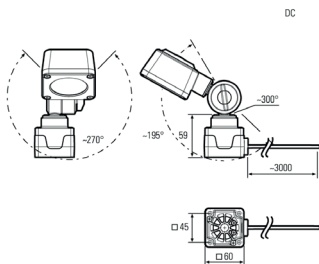

Lampenlebensdauer in Betriebsstunden (L80/B10)


LED Maschinenleuchte
LED machine luminaire



CENALED SPOT DC, Gelenkkopf
Joint head luminaire

Item number:	121012-03
EAN:	4260556623733
Customs tariff number:	94054099

Order number:	121012-03
Model:	CENALED SPOT
Type:	LED joint head luminaire
Illuminant:	High Power LED
Power consumption:	~8,5 W
Lamp luminous flux:	1120 lm
Lamp luminous efficiency:	134 lm/W
Light distribution:	direct
Light colour:	neutral white (5000K)
Connected load:	24V DC \pm 10%
Power supply:	-
Connection (connector):	connection cable 3 m, oelflex, with open ends
Degree of protection:	IP67
Class of protection:	III
Beam angle (optics):	30°
Operating temperature:	-10... +50 °C
Colour rendering (Ra):	> 80
Lamps lifetime:	> 60,000 h
Housing material:	aluminium (powder-finished)
Cover material:	ESG 3,8 mm, shatterproof
Weight (net):	400 g
Gross weight:	550 g
Risk group (DIN EN 62471):	free group
Mounting accessories:	magnetic holder optional
Dimmable:	yes, via push button at the luminaire head , ON/OFF and dimming
Made in:	Germany
Feature:	handy LED luminaire with high degree of protection

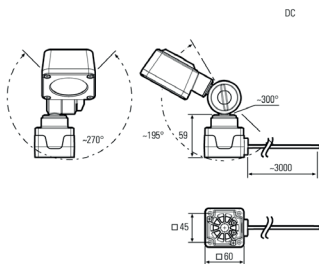

Lamps lifetime in operation hours (L80/B10)