

## LED Arbeitsplatzleuchte


### LED workplace luminaire



## UNILED SL AC, 545 mm, 220-240V AC, SCHUKO, Abdeckung Mikroprismen

<b>Artikel-Nr.:</b>	110914-62
<b>EAN:</b>	4260556623542
<b>Zolltarifnr.:</b>	94054099

<b>Bestellnr.:</b>	110914-62
<b>Modell:</b>	UNILED SL
<b>Bauform:</b>	LED System- und Arbeitsplatzleuchte
<b>Leuchtmittel:</b>	SMD LED
<b>Lampenleistung:</b>	~17 W
<b>Lampenlichtstrom:</b>	2060 lm
<b>Lampenlichtausbeute:</b>	127 lm/W
<b>Lichtverteilung:</b>	direkt
<b>Lichtfarbe:</b>	Tageslichtweiß (5200 - 5700K)
<b>Anschlusswert Leuchte:</b>	220-240V AC ± 10%, 50-60 Hz
<b>Betriebsgerät:</b>	integriert
<b>Anschluss Leuchte:</b>	SCHUKO + 3m Leitung
<b>Schutzart:</b>	IP50
<b>Schutzklasse:</b>	I
<b>Entblendung:</b>	Mikroprismen
<b>Abstrahlwinkel:</b>	100°
<b>Betriebstemperatur:</b>	-10... +60 °C
<b>Farbwiedergabe (Ra):</b>	> 80
<b>Lampenlebensdauer:</b>	> 50.000 h
<b>Material Gehäuse:</b>	Aluminium
<b>Material Abdeckung:</b>	Kunststoff Mikroprismen
<b>Höhe [B] x Breite [C]:</b>	35 mm x 85 mm
<b>Länge [A]:</b>	545 mm / 575 mm
<b>Gewicht:</b>	950 g
<b>Bruttogewicht:</b>	1400 g
<b>Risikogruppe:</b>	Gruppe 1
<b>Befestigungszubehör:</b>	optional
<b>Dimmbar:</b>	optional über Zubehör
<b>Kennzeichnung:</b>	CE
<b>Gefertigt in:</b>	Deutschland
<b>Besonderheit:</b>	Hohe Lichtstreuung, universell einsetzbar

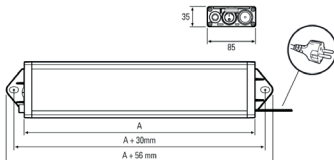

Lampenlebensdauer in Betriebstunden (L80/B10)


LED Arbeitsplatzleuchte  
LED workplace luminaire



**UNILED SL AC, 545 mm, 220-240V AC, SCHUKO,  
micro prisms cover**

<b>Item number:</b>	110914-62
<b>EAN:</b>	4260556623542
<b>Customs tariff number:</b>	94054099

<b>Order number:</b>	110914-62
<b>Model:</b>	UNILED SL
<b>Type:</b>	LED system luminaire and workplace lighting
<b>Illuminant:</b>	SMD LED
<b>Power consumption:</b>	~17 W
<b>Lamp luminous flux:</b>	2060 lm
<b>Lamp luminous efficiency:</b>	127 lm/W
<b>Light distribution:</b>	direct
<b>Light colour:</b>	daylight white (5200 - 5700K)
<b>Connected load:</b>	220-240V AC ± 10%, 50-60 Hz
<b>Power supply:</b>	inbuilt
<b>Connection (connector):</b>	connection cable 3 m with angled SCHUKO plug
<b>Degree of protection:</b>	IP50
<b>Class of protection:</b>	I
<b>Glare-free</b>	micro prisms
<b>Beam angle (optics):</b>	100°
<b>Operating temperature:</b>	-10... +60 °C
<b>Colour rendering (Ra):</b>	> 80
<b>Lamps lifetime:</b>	> 50,000 h
<b>Housing material:</b>	aluminium
<b>Cover material:</b>	micro prisms cover
<b>Height [B] x Width [C]:</b>	35 mm x 85 mm
<b>Length [A]:</b>	545 mm / 575 mm
<b>Weight (net):</b>	950 g
<b>Gross weight:</b>	1400 g
<b>Risk group (DIN EN 62471):</b>	group 1
<b>Mounting accessories:</b>	optional
<b>Dimmable:</b>	via optional accessory
<b>Marking:</b>	CE
<b>Made in:</b>	Germany
<b>Feature:</b>	high light diffusion, universally applicable

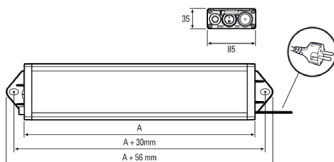

Lamps lifetime in operation hours (L80/B10)