


## LED Arbeitsplatzleuchte


### LED workplace luminaire

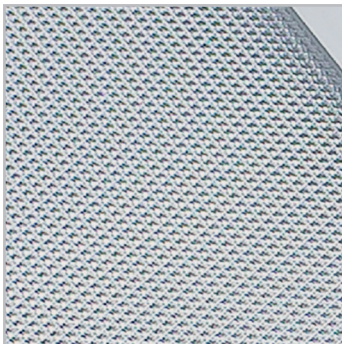

## UNILED SL AC, 570 mm, 220-240V AC, Zugpendel


<b>Artikel-Nr.:</b>	110914-82
<b>EAN:</b>	4260556623573
<b>Zolltarifnr.:</b>	94054099

<b>Bestellnr.:</b>	110914-82
<b>Modell:</b>	UNILED SL
<b>Bauform:</b>	LED Arbeitsplatzdeckenleuchte
<b>Leuchtmittel:</b>	SMD LED
<b>Lampenleistung:</b>	~17 W
<b>Lampenlichtstrom:</b>	2060 lm
<b>Lampenlichtausbeute:</b>	127 lm/W
<b>Lichtverteilung:</b>	direkt
<b>Lichtfarbe:</b>	Tageslichtweiß (5200 - 5700K)
<b>Anschlusswert Leuchte:</b>	220-240V AC ± 10%, 50-60 Hz
<b>Betriebsgerät:</b>	integriert
<b>Anschluss Leuchte:</b>	1 Paar Zugpendel, 1x 230V Deckenübergabepunkt, 2 offene Kabelenden
<b>Schutzart:</b>	IP50
<b>Schutzklasse:</b>	I
<b>Entblendung:</b>	Mikroprismen
<b>Abstrahlwinkel:</b>	100°
<b>Betriebstemperatur:</b>	-10... +60 °C
<b>Farbwiedergabe (Ra):</b>	> 80
<b>Lampenlebensdauer:</b>	> 50.000 h
<b>Material Gehäuse:</b>	Aluminium
<b>Material Abdeckung:</b>	Kunststoff Mikroprismen
<b>Höhe [B] x Breite [C]:</b>	35 mm x 85 mm
<b>Länge [A]:</b>	570 mm
<b>Zugpendel Auszugsbereich:</b>	~740 mm - 1900 mm
<b>Gewicht:</b>	1150
<b>Bruttogewicht:</b>	1600 g
<b>Risikogruppe:</b>	Gruppe 1
<b>Befestigungszubehör:</b>	optional
<b>Kennzeichnung:</b>	CE
<b>Gefertigt in:</b>	Deutschland
<b>Besonderheit:</b>	Lichtintensität manuell über Zugpendel einstellbar

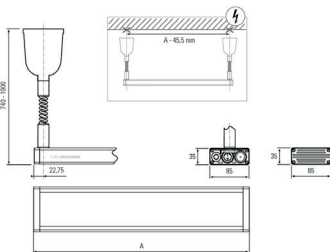

Lampenlebensdauer in Betriebsstunden (L80/B10)


LED Arbeitsplatzleuchte  
LED workplace luminaire

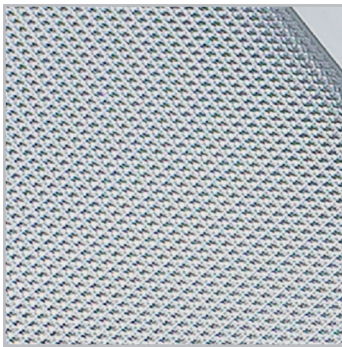

UNILED SL AC, 570 mm, 220-240V AC,  
adjustable pull pendants

Item number:	110914-82
EAN:	4260556623573
Customs tariff number:	94054099

Order number:	110914-82
Model:	UNILED SL
Type:	LED ceiling light for workplaces
Illuminant:	SMD LED
Power consumption:	~17 W
Lamp luminous flux:	2060 lm
Lamp luminous efficiency:	127 lm/W
Light distribution:	direct
Light colour:	daylight white (5200 - 5700K)
Connected load:	220-240V AC ± 10%, 50-60 Hz
Power supply:	inbuilt
Connection (connector):	1 pair of adjustable pull pendants, 1x 230V ceiling transfer point via two open cable ends
Degree of protection:	IP50
Class of protection:	I
Glare-free	micro prisms
Beam angle (optics):	100°
Operating temperature:	-10... +60 °C
Colour rendering (Ra):	> 80
Lamps lifetime:	> 50,000 h
Housing material:	aluminium
Cover material:	micro prisms cover
Height [B] x Width [C]:	35 mm x 85 mm
Length [A]:	570 mm
adjustable pull pendants Auszugsbereich:	~740 mm - 1900 mm
Weight (net):	1150
Gross weight:	1600 g
Risk group (DIN EN 62471):	group 1
Mounting accessories:	optional
Marking:	CE
Made in:	Germany
Feature:	light intensity variable via adjustable pull pendants

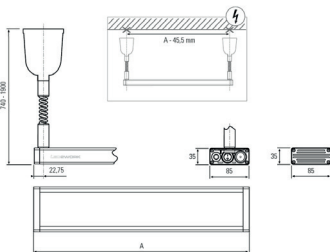

Lamps lifetime in operation hours (L80/B10)