


## LED Arbeitsplatzleuchte

### LED workplace luminaire

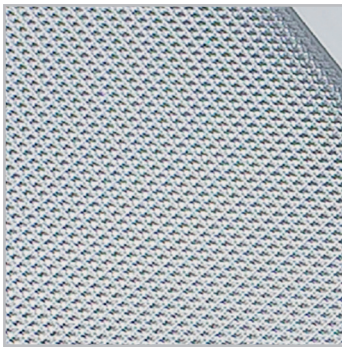

## UNILED SL AC, 570 mm, 220-240V AC, Zugpendel

**Artikel-Nr.:** 110914-85

**EAN:** 4260556624822

**Zolltarifnr.:** 94054099

**Bestellnr.:** 110914-85

**Modell:** UNILED SL

**Bauform:** LED Arbeitsplatzdeckenleuchte

**Leuchtmittel:** SMD LED

**Lampenleistung:** ~17 W

**Lampenlichtstrom:** 2060 lm

**Lampenlichtausbeute:** 127 lm/W

**Lichtverteilung:** direkt

**Lichtfarbe:** Tageslichtweiß (5200 - 5700K)

**Anschlusswert Leuchte:** 220-240V AC  $\pm$  10%, 50-60 Hz

**Betriebsgerät:** integriert

**Anschluss Leuchte:** 1 Paar Zugpendel, 1x 230V Deckenübergabepunkt, 2 offene Kabelenden

**Schutzart:** IP50

**Schutzklasse:** I

**Entblendung:** Mikroprismen

**Abstrahlwinkel:** 100°

**Betriebstemperatur:** -10... +60 °C

**Farbwiedergabe (Ra):** > 80

**Lampenlebensdauer:** > 50.000 h

**Material Gehäuse:** Aluminium

**Material Abdeckung:** Kunststoff Mikroprismen

**Höhe [B] x Breite [C]:** 35 mm x 85 mm

**Länge [A]:** 570 mm

**Zugpendel Auszugsbereich:** ~340 mm - 1300 mm

**Gewicht:** 1150

**Bruttogewicht:** 1600 g


**Risikogruppe:** Gruppe 1

**Befestigungszubehör:** optional

**Kennzeichnung:** CE


**Gefertigt in:** Deutschland

**Besonderheit:** Lichtintensität manuell über Zugpendel einstellbar

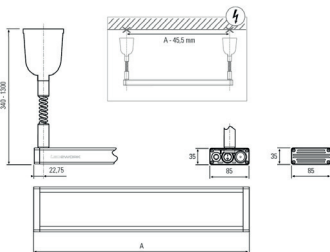

Lampenlebensdauer in Betriebsstunden (L80/B10)


LED Arbeitsplatzleuchte  
LED workplace luminaire

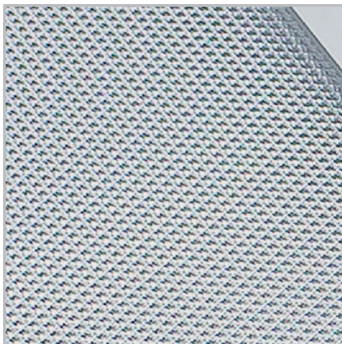

**UNILED SL AC, 570 mm, 220-240V AC,  
adjustable pull pendants**

<b>Item number:</b>	110914-85
<b>EAN:</b>	4260556624822
<b>Customs tariff number:</b>	94054099

<b>Order number:</b>	110914-85
<b>Model:</b>	UNILED SL
<b>Type:</b>	LED ceiling light for workplaces
<b>Illuminant:</b>	SMD LED
<b>Power consumption:</b>	~17 W
<b>Lamp luminous flux:</b>	2060 lm
<b>Lamp luminous efficiency:</b>	127 lm/W
<b>Light distribution:</b>	direct
<b>Light colour:</b>	daylight white (5200 - 5700K)
<b>Connected load:</b>	220-240V AC ± 10%, 50-60 Hz
<b>Power supply:</b>	inbuilt
<b>Connection (connector):</b>	1 pair of adjustable pull pendants, 1x 230V ceiling transfer point via two open cable ends
<b>Degree of protection:</b>	IP50
<b>Class of protection:</b>	I
<b>Glare-free</b>	micro prisms
<b>Beam angle (optics):</b>	100°
<b>Operating temperature:</b>	-10... +60 °C
<b>Colour rendering (Ra):</b>	> 80
<b>Lamps lifetime:</b>	> 50,000 h
<b>Housing material:</b>	aluminium
<b>Cover material:</b>	micro prisms cover
<b>Height [B] x Width [C]:</b>	35 mm x 85 mm
<b>Length [A]:</b>	570 mm
<b>adjustable pull pendants Auszugsbereich:</b>	~340 mm - 1300 mm
<b>Weight (net):</b>	1150
<b>Gross weight:</b>	1600 g
<b>Risk group (DIN EN 62471):</b>	group 1
<b>Mounting accessories:</b>	optional
<b>Marking:</b>	CE
<b>Made in:</b>	Germany
<b>Feature:</b>	light intensity variable via adjustable pull pendants

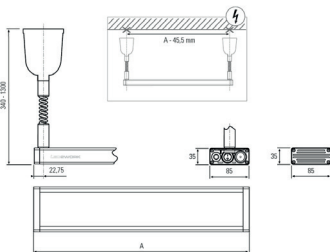

Lamps lifetime in operation hours (L80/B10)