


LED Arbeitsplatzleuchte

LED workplace luminaire

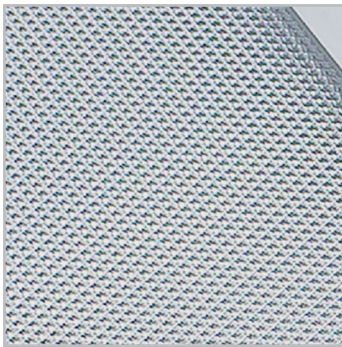

UNILED SL AC, 1070 mm, 220-240V AC, Zugpendel

Artikel-Nr.: 110914-86

EAN: 4260556624839

Zolltarifnr.: 94054099

Bestellnr.: 110914-86

Modell: UNILED SL

Bauform: LED System- und Arbeitsplatzleuchte

Leuchtmittel: SMD LED

Lampenleistung: ~34 W

Lampenlichtstrom: 5120 lm

Lampenlichtausbeute: 127 lm/W

Lichtverteilung: direkt

Lichtfarbe: Tageslichtweiß (5200 - 5700K)

Anschlusswert Leuchte: 220-240V AC ± 10%, 50-60 Hz

Betriebsgerät: integriert

Anschluss Leuchte: 1 Paar Zugpendel, 1x 230V Deckenübergabepunkt, 2 offene Kabelenden

Schutzart: IP50

Schutzklasse: I

Entblendung: Mikroprismen

Abstrahlwinkel: 100°

Betriebstemperatur: -10... +60 °C

Farbwiedergabe (Ra): > 80

Lampenlebensdauer: > 50.000 h

Material Gehäuse: Aluminium

Material Abdeckung: Kunststoff Mikroprismen

Höhe [B] x Breite [C]: 35 mm x 85 mm

Länge [A]: 1070 mm

Zugpendel Auszugsbereich: ~340 mm - 1300 mm

Gewicht: 1900 g

Bruttogewicht: 2750 g


Risikogruppe: Gruppe 1

Dimmbar: optional über Zubehör

Kennzeichnung: CE


Gefertigt in: Deutschland

Besonderheit: Lichtintensität über Zugpendel einstellbar

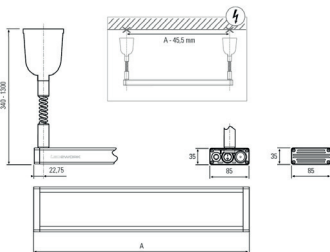

Lampenlebensdauer in Betriebstunden (L80/B10)


LED Arbeitsplatzleuchte
LED workplace luminaire

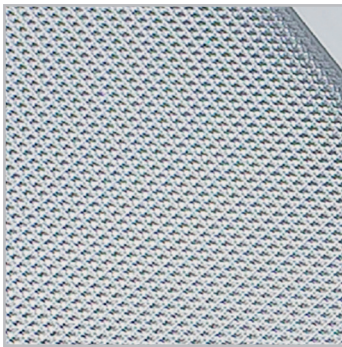

UNILED SL AC, 1070 mm, 220-240V AC,
adjustable pull pendants

Item number:	110914-86
EAN:	4260556624839
Customs tariff number:	94054099

Order number:	110914-86
Model:	UNILED SL
Type:	LED system luminaire and workplace lighting
Illuminant:	SMD LED
Power consumption:	~34 W
Lamp luminous flux:	5120 lm
Lamp luminous efficiency:	127 lm/W
Light distribution:	direct
Light colour:	daylight white (5200 - 5700K)
Connected load:	220-240V AC ± 10%, 50-60 Hz
Power supply:	inbuilt
Connection (connector):	1 pair of adjustable pull pendants, 1x 230V ceiling transfer point via two open cable ends
Degree of protection:	IP50
Class of protection:	I
Glare-free	micro prisms
Beam angle (optics):	100°
Operating temperature:	-10... +60 °C
Colour rendering (Ra):	> 80
Lamps lifetime:	> 50,000 h
Housing material:	aluminium
Cover material:	micro prisms cover
Height [B] x Width [C]:	35 mm x 85 mm
Length [A]:	1070 mm
adjustable pull pendants Auszugsbereich:	~340 mm - 1300 mm
Weight (net):	1900 g
Gross weight:	2750 g
Risk group (DIN EN 62471):	group 1
Dimmable:	via optional accessory
Marking:	CE
Made in:	Germany
Feature:	light intensity variable via adjustable pull pendants

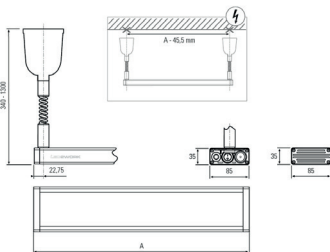

Lamps lifetime in operation hours (L80/B10)