



LED Arbeitsplatzleuchte LED workplace luminaire

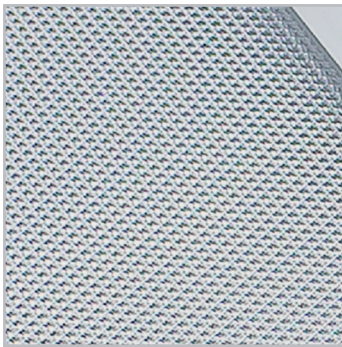


UNILED SL AC, 1570 mm, 220-240V AC, Zugpendel

Artikel-Nr.:	110914-87
EAN:	4260556624846
Zolltarifnr.:	94054099
Bestellnr.:	110914-87
Modell:	UNILED SL
Bauform:	LED System- und Arbeitsplatzleuchte
Leuchtmittel:	SMD LED
Lampenleistung:	~51 W
Lampenlichtstrom:	6180 lm
Lampenlichtausbeute:	127 lm/W
Lichtverteilung:	direkt
Lichtfarbe:	Tageslichtweiß (5200 - 5700K)
Anschlusswert Leuchte:	220-240V AC ± 10%, 50-60 Hz
Betriebsgerät:	integriert
Anschluss Leuchte:	1 Paar Zugpendel, 1x 230V Deckenübergabepunkt, 2 offene Kabelenden
Schutzart:	IP50
Schutzklasse:	I
Entblendung:	Mikroprismen
Abstrahlwinkel:	100°
Betriebstemperatur:	-10... +60 °C
Farbwiedergabe (Ra):	> 80
Lampenlebensdauer:	> 50.000 h
Material Gehäuse:	Aluminium
Material Abdeckung:	Kunststoff Mikroprismen
Höhe [B] x Breite [C]:	35 mm x 85 mm
Länge [A]:	1570 mm
Zugpendel Auszugsbereich:	~340 mm - 1300 mm
Gewicht:	2700 g
Bruttogewicht:	3900 g
Risikogruppe:	Gruppe 1
Befestigungszubehör:	optional
Dimmbar:	optional über Zubehör
Kennzeichnung:	CE
Gefertigt in:	Deutschland
Besonderheit:	Hohe Lichtsteuerung, universell einsetzbar

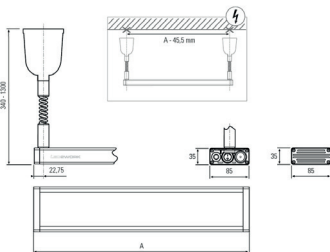

Lampenlebensdauer in Betriebstunden (L80/B10)


LED Arbeitsplatzleuchte
LED workplace luminaire

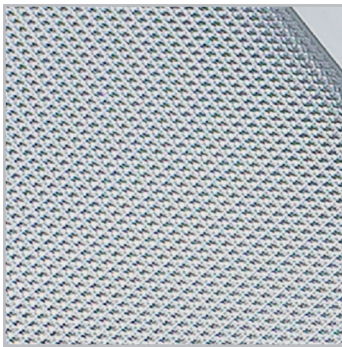

UNILED SL AC, 1570 mm, 220-240V AC,
adjustable pull pendants

Item number:	110914-87
EAN:	4260556624846
Customs tariff number:	94054099

Order number:	110914-87
Model:	UNILED SL
Type:	LED system luminaire and workplace lighting
Illuminant:	SMD LED
Power consumption:	~51 W
Lamp luminous flux:	6180 lm
Lamp luminous efficiency:	127 lm/W
Light distribution:	direct
Light colour:	daylight white (5200 - 5700K)
Connected load:	220-240V AC ± 10%, 50-60 Hz
Power supply:	inbuilt
Connection (connector):	1 pair of adjustable pull pendants, 1x 230V ceiling transfer point via two open cable ends
Degree of protection:	IP50
Class of protection:	I
Glare-free	micro prisms
Beam angle (optics):	100°
Operating temperature:	-10... +60 °C
Colour rendering (Ra):	> 80
Lamps lifetime:	> 50,000 h
Housing material:	aluminium
Cover material:	micro prisms cover
Height [B] x Width [C]:	35 mm x 85 mm
Length [A]:	1570 mm
adjustable pull pendants Auszugsbereich:	~340 mm - 1300 mm
Weight (net):	2700 g
Gross weight:	3900 g
Risk group (DIN EN 62471):	group 1
Mounting accessories:	optional
Dimmable:	via optional accessory
Marking:	CE
Made in:	Germany
Feature:	high light diffusion, universally applicable

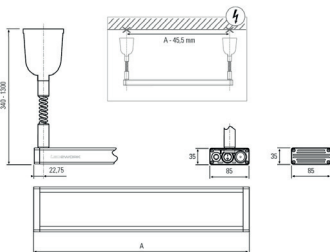

Lamps lifetime in operation hours (L80/B10)